


Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	1/0 STR/FLEX
Wire Type	Stranded Copper: Class B & C, Compact, Class G, H, I, K, M, Locomotive
Wire Strip Length	1-1/16 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	PINK
Panduit Die Index No. on Barrel	P42
Alternate Industry Die Index No. () on Barrel	(12)

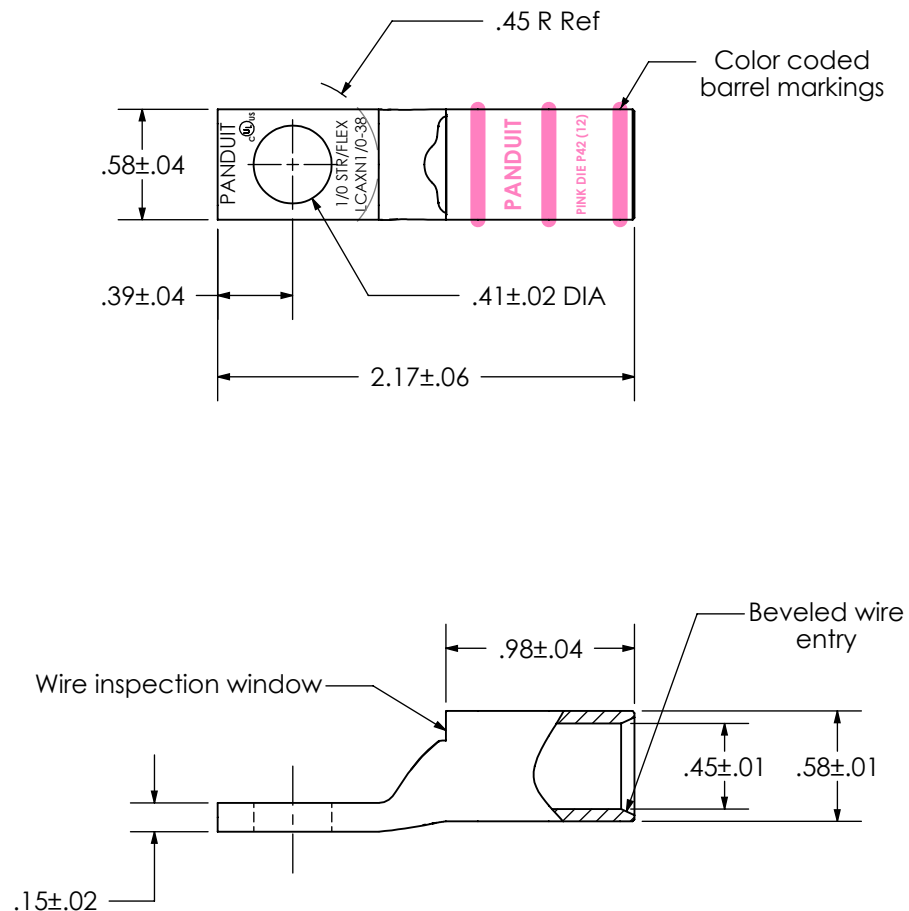

							PANDUIT CORP. TINLEY PARK, ILLINOIS	
							LCAXN1/0-38-X Copper Lug - One-Hole, Narrow Tongue, Standard Flex Barrel	
00	12/16	JHNU	JHNU	RGB	DRAWING RELEASED	00159NBK-LCAXN1/0-38-CUST		
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN	SCALE N/A	DRAWING NO / CAD FILE LCAXN1_0-38-CUST