

(1,00 mm) .0394"

FSI SERIES

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?FSI

Insulator Material:

Liquid Crystal

Polymer

Contact Material:

BeCu

Current Rating:

2.4A per contact

@ 80°C ambient

Operating Temp Range:

-55°C to +125°C

Plating:

Au over 50µ" (1,27 µm) Ni

RoHS Compliant:

Yes

Processing:

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0,10 mm) .004" max (05-30)

(0,15 mm) .006" max (50)

Compression Board:


Gold Pads required




APPLICATION SPECIFIC OPTION

Metric insert, no alignment pin, top side alignment pin and bottom side alignment pin. Call Samtec.

Choice of board stacking profiles

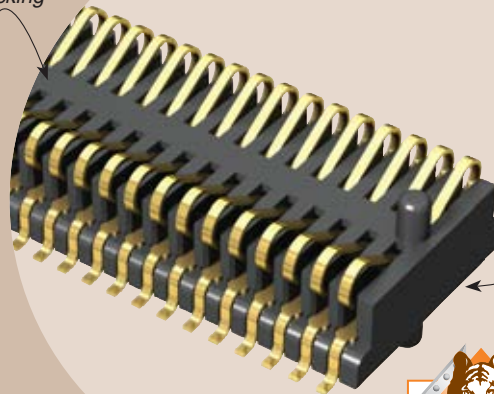

Short version or optional threaded inserts

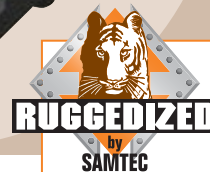

• Threaded insert option

FSI

1

PINS PER ROW

BODY HEIGHT

PLATING OPTION

10, 20, 30 & 50
(Insert/Screw Option)
05, 10, 20, 30, 50
(Short Version)

—03
= 3,00 mm
—06
= 6,00 mm
—10
= 10,00 mm

 
—G
= 10µ" (0,25 µm) Gold
(—03 only)
—L
= 10µ" (0,25 µm)
Gold on contact,
Matte Tin on tail
(Not available with
—03 body height)

Note: Applications requiring 40-50 positions without threaded inserts, please contact Samtec Interconnect Processing Group.




Note: Some lengths, styles and options are non-standard, non-returnable.

Also Available



Low Profile
See SEI Series.



.100"
(2,54mm)
Pitch
See SIB Series.

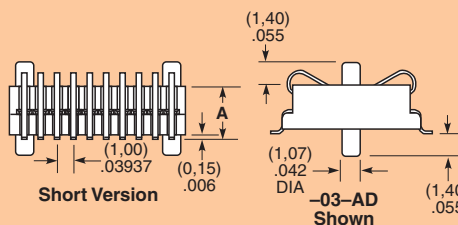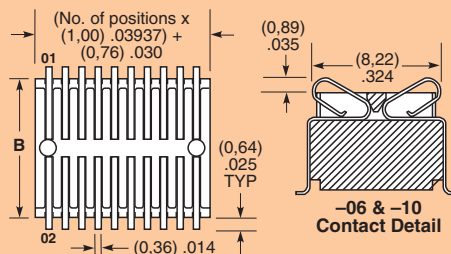 

Double Row Version —03, —06, —10

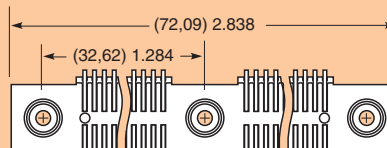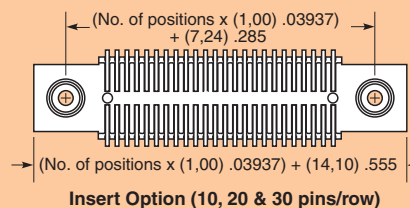

BODY HEIGHT	A	B
—03	(3,00) .118	(8,76) .345
—06	(6,00) .236	(9,02) .355
—10	(10,00) .394	(9,02) .355

Note: Other Gold plating options available. Contact Samtec.





Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM


SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
 SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683



FSI-130-03-G-S-AD

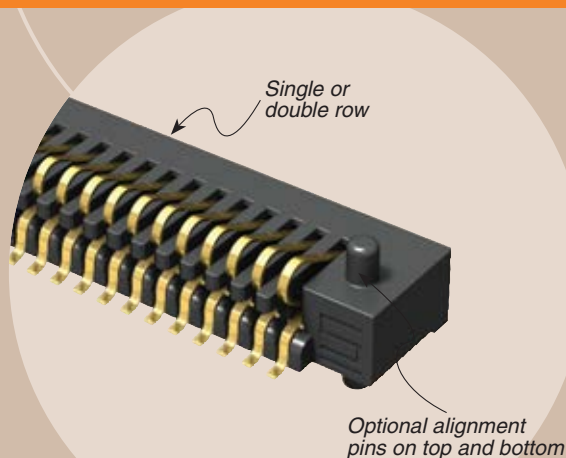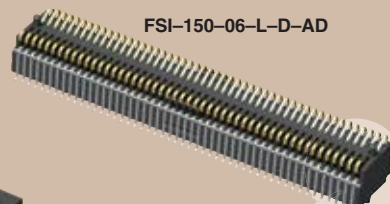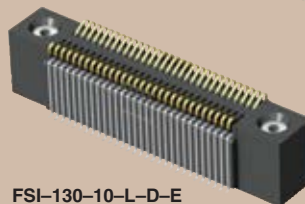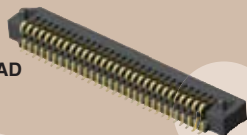

Choice of board stacking profiles

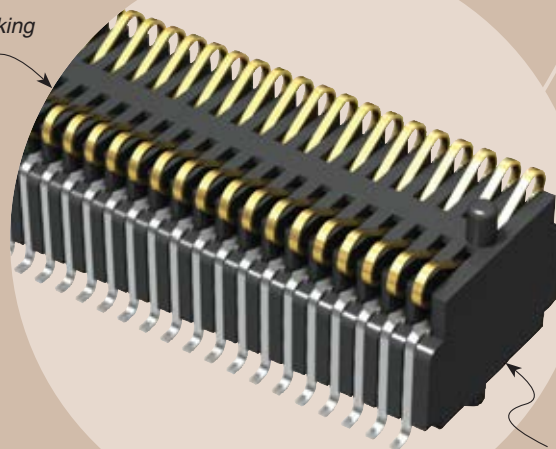

Short version or optional threaded inserts

ROW OPTION

-S
= Single Row
(Available with 5, 10 & 20 pins with -AD alignment pin)

-D
= Double Row

INSERT OPTION

Leave blank for Short Version
(No screw down inserts or holes)

-E
= #2-56 x 1/16" screw thread

ALIGNMENT OPTION

Leave blank for no Alignment Pin

-AD
= Alignment Pin Top & Bottom


OTHER OPTION

-WT
= Weld Tab
(Available with -S row option & -06 & -10 body height only)




-K
= Polyimide Film Pick & Place Pad
(50 position with threaded insert option only)

-P
= Plastic Pick & Place Pad
(5,08 mm) .200" x (12,45 mm) .490"
(50 not available with -E)
(Not available with -S row option or -03 body height)




-TR
= Tape & Reel Packaging

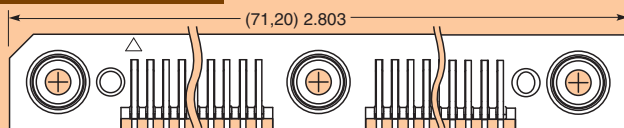

Insert Option (50 pins/row)

 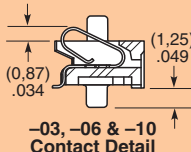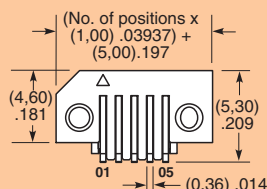

Short Version

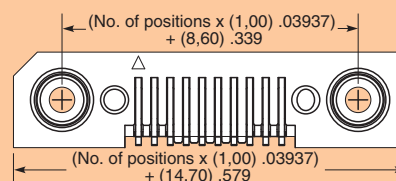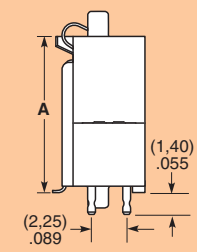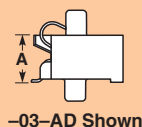

Insert Option (10, 20 & 30 pins/row)

Single Row Version -03, -06, -10

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683