
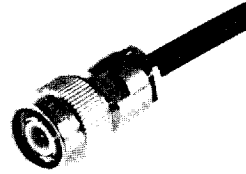


COMMERCIAL TNC

CABLE CLAMP TYPE FOR FLEXIBLE CABLE

Straight plug


CABLE GROUP	.197 (5) / 50
PART NUMBER	R 143 007 161●
Impedance	50Ω
Assembly instructions	M07 page 32

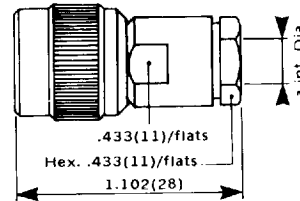


CRIMP TYPE FOR FLEXIBLE CABLE

Bulkhead panel sealed straight jacks

CABLE GROUP	.102 (2.6) / 50 S. scr.	
PART NUMBER	R 143 331 161	
Impedance	50Ω	
Assembly instructions	M05 page 30	
Panel drilling	P11 + P12 page 18	

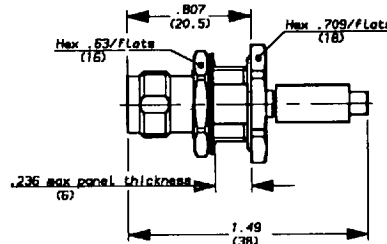



CABLE GROUP	.197 (5) / 50 S. scr.	.236 (6) / 75
PART NUMBER	R 143 332 161	R 144 334 161●
Impedance	50Ω	75Ω
Assembly instructions	M03 page 28	
Panel drilling	P11 + P12 page 18	

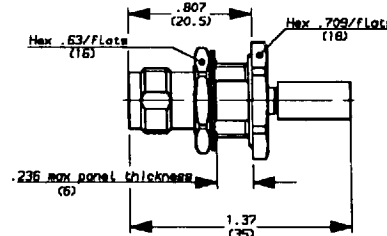

RECEPTACLES

Bulkhead straight jacks

PART NUMBER	R 143 563 161●	R 143 574 161●
Captive contact	YES	
Insulated	NO	YES
Panel drilling	P13 page 18	

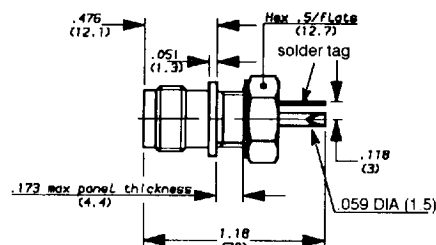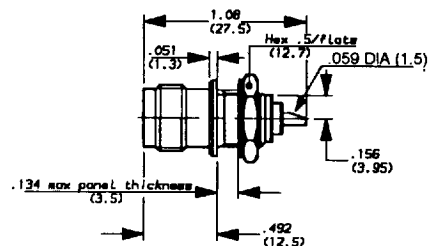

● Manufactured upon request.