
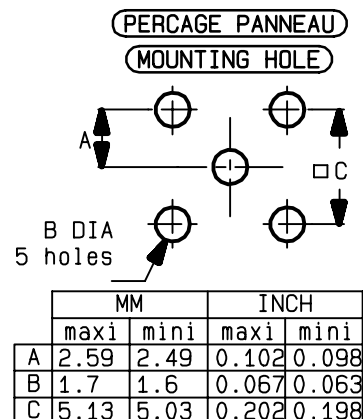


STRAIGHT PLUG RECEPTACLE FOR PCB SOLDER LEGS - PACK. 100

R128.425.820

SERIES BMA COM

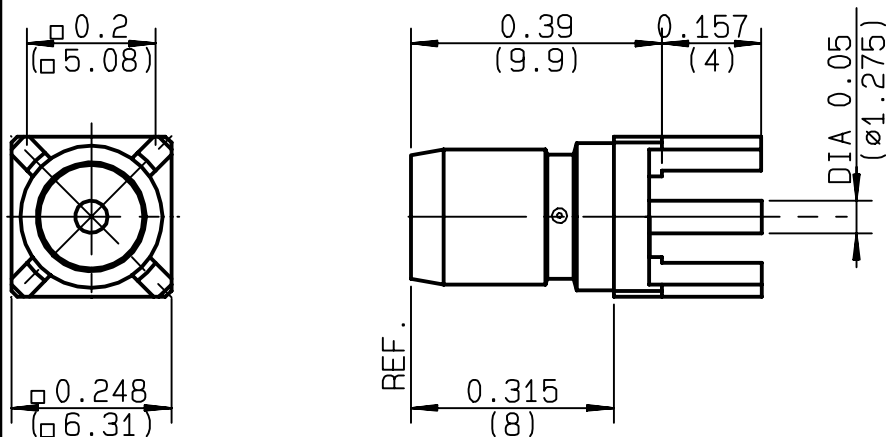

NOMINAL IMPEDANCE	50	Ω
FREQUENCY RANGE	0-22	GHz
TEMPERATURE RATING	-65/+125	$^{\circ}\text{C}$
V.S.W.R	1.25* + 0 x F(GHz)Maxi	
RF INSERTION LOSS	0.07 $\sqrt{F}$ (GHz) dB Maxi	
VOLTAGE RATING	350	Veff Maxi
DIELECTRIC WITHSTANDING VOLTAGE	1000	Veff Mini
INSULATION RESISTANCE	5000	M Ω Mini
HERMETIC SEAL	NA	Atm.cm ³ /s
LEAKAGE (pressurized only)	NA	
MECHANICAL DURABILITY	500	Cycles
WEIGHT	1.35	gr
SPECIFICATION	* R.O.S 1.25 MAXI 0-10 GHz * V.S.W.R 1.25 MAX 0-10 GHz	

CABLES :

OTHERS CHARACTERISTICS

*** de 0 -10 GHz**

CABLE RETENTION	NA	N Mini
CENTER CONTACT RETENTION		
Axial force - mating end	18	N Mini
Axial force - opposite end	18	N Mini
Torque	NA	cm.N Mini
RECOMMENDED TORQUES		
Mating	NA	cm.N
Panel nut	NA	cm.N
Clamp nut	NA	cm.N

CONNECTOR PARTS	MATERIALS	FINISH	(all values are given in micrometers)
BODY	BRASS	GOLD 0.5 OVER NICKEL 2	
OUTER CONTACT			
CENTER CONTACT	BRASS	GOLD 1.3 OVER COPPER 2	
INSULATOR	PTFE	-	
GASKET		-	
OTHERS PIECES			

BAFFERT

ISSUE	CREATION DATE	FILE PART-NUMBER
9926A00	24/06/1997	EPC96-06



RADIALL®

The information given here is subject to change without notice.
Design changes may be in order to improve the product.

Connect to the future