

### STRAIGHT FEMALE PCB RECEPTACLE

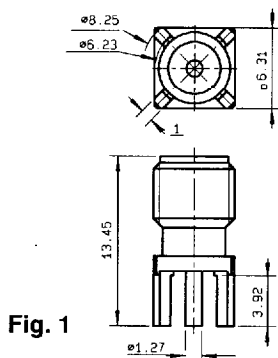
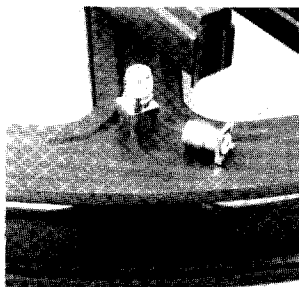


Fig. 1

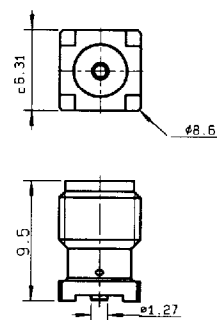


Fig. 2

| part number   | fig. | PCB pattern | finish               | note                                        |
|---------------|------|-------------|----------------------|---------------------------------------------|
| R124 426 120  | 1    | P 03        | BBR                  |                                             |
| R124 426 121● | 1    | P 03        | BBR + Tin-lead 60/40 |                                             |
| R124 426 123  | 1    | P 03        | Gold                 |                                             |
| R124 426 850  | 1    | P 03        | BBR                  | Tube of 78 pieces                           |
| R124 426 853  | 1    | P 03        | Gold                 | Tube of 78 pieces                           |
| R124 427 000  | 2    | M 09        | Gold                 | Surface mount / Unit packaging              |
| R124 427 800  | 2    | M 09        | Gold                 | Surface mount / Tape and reel of 100 pieces |
| R124 427 850  | 2    | M 09        | Gold                 | Surface mount / tube of 78 pieces           |

### RIGHT ANGLE FEMALE PCB RECEPTACLE

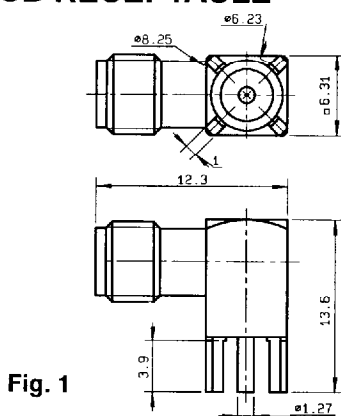


Fig. 1

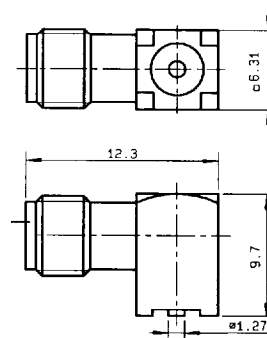


Fig. 2

| part number   | fig. | PCB pattern | finish               | note                                        |
|---------------|------|-------------|----------------------|---------------------------------------------|
| R124 680 120  | 1    | P 03        | BBR                  |                                             |
| R124 680 123  | 1    | P 03        | Gold                 |                                             |
| R124 680 130● | 1    | P 03        | BBR + Tin lead 60/40 |                                             |
| R124 680 850  | 1    | P 03        | BBR                  | Tube of 40 pieces                           |
| R124 680 853  | 1    | P 03        | Gold                 | Tube of 40 pieces                           |
| R124 681 000  | 2    | M 09        | Gold                 | Surface mount / Unit packaging              |
| R124 681 800  | 2    | M 09        | Gold                 | Surface mount / Tape and reel of 100 pieces |
| R124 681 850  | 2    | M 09        | Gold                 | Surface mount / tube of 40 pieces           |