 



SMB LOCK




STRAIGHT PLUG FULL CRIMP TYPE FOR FLEXIBLE CABLES

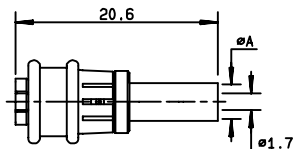


cable type	cable	part number	A	captive center contact
2.6/50/S	RG174-188-316 / SHF 2.7 TU*	R117 082 807	3.25	yes
2.6/50/D	RD316 / SHF 2.7 TD/1*	R117 083 807	3.5	yes
5/50/S	RG 58 - 141 / SHF 142	R117 086 827 •	5.55	yes
5/50/D	RG 142 - 223 - 400	R117 087 827 •	5.55	yes

STRAIGHT PLUG SOLDER TYPE FOR SEMI-RIGID CABLE

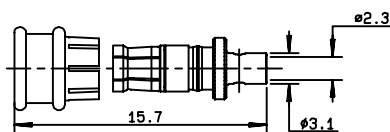

cable type	cable	part number	captive center contact
.085"	RG 405/U	R117 053 807	no

RIGHT ANGLE PLUG CRIMP TYPE FOR FLEXIBLE CABLES

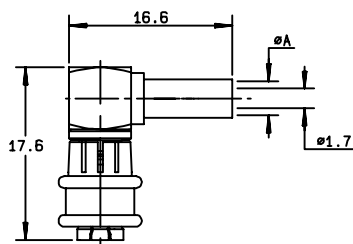

cable type	cable	part number	A	captive center contact
2.6/50/S	RG174-188-316 / SHF 2.7 TU*	R117 186 807	3.25	yes
2.6/50/D	RD316 / SHF 2.7 TD/1*	R117 187 807	3.5	yes
5/50/S	RG 58 - 141 / SHF 142	R117 178 827 •	5.55	yes
5/50/D	RG 142 - 223 - 400	R117 179 827 •	5.55	yes

• upon request

* These RADIAL cables are "low loss-low cost" option to RG cables. Their main advantages are : **low loss level, low intermod level, high shielding effectiveness, halogen free**. Part number : SHF 2.7 TU : **C291 999 904** - SHF 2.7 TD/1 : **C 291 999 905** - SHF 142 : **C291 325 290**.