


08098800 BATTERY DISCONNECT SWITCHES

250A • SPST • IP69K • M10 Studs

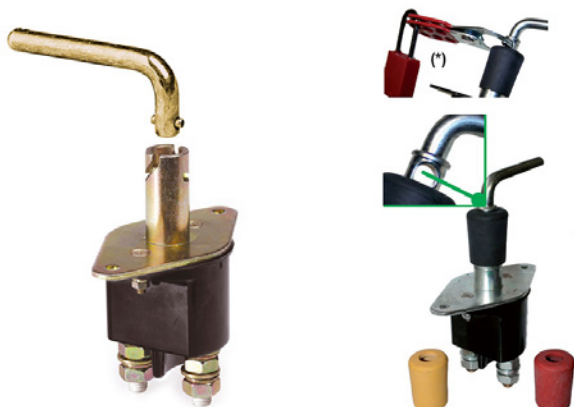

Description

250A Manual battery master switch with removable or fixed handle. Available with weather protective boots.

080988 00

Base unit with removable handle

080988 81

Unit with removable handle and chain. Equipped with red, yellow and black rubber boots for weather protection and to help identify different applications. Interchangeable with Bosch 0341002003 switches

080988 82

Unit with fixed handle and integrated lock-out tag-out. Equipped with red, yellow and black rubber boots for weather protection and to help identify different applications. Newest design that does not require the use of additional accessories such as a LockSafe device. Interchangeable with Bosch 0341002003 switches

Features/Benefits

- 250A continuous current rating
- Interchangeable with Bosch master disconnect switches

Specifications

Max Operating Voltage:	24V DC
Max Continuous Current:	250A
Intermittent Current:	2500A at 3 sec
Operating Temp:	-40°C to +85°C
Ingress Protection:	IP65 IP69K (with key boots)
Contacts:	Copper
Terminals:	M10


Applications

- Heavy Truck
- Off-Road
- Emergency Vehicles
- Material Handling
- Mining
- Agricultural
- Marine
- Construction

Web Resources

Download 2D prints and additional technical resources at:
littelfuse.com/ManualBatterySwitches

Electrical Diagram

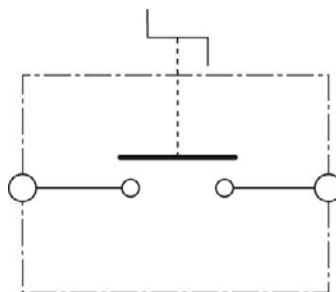

Ordering Information

PART NUMBERS		VOLTAGE	AMPERAGE	CIRCUITRY	MOUNTING	INGRESS	NOTES
BULK	BOXED						
08098800	08098800-BX	24V DC	250A	SPST	Flange Mount	IP65	Removable Handle
08098881	08098881-BX	24V DC	250A	SPST	Flange Mount	IP65/IP69K	Removable Handle w/ Chain Cap to Cover when Key is Removed Red & Yellow Boots.
08098882	08098882-BX	24V DC	250A	SPST	Flange Mount	IP65/IP69K	Fixed Handle w/ Integrated Lock-Out Tag-Out Black, Red & Yellow Boots

Dimensions in millimeters

