



C2 Series

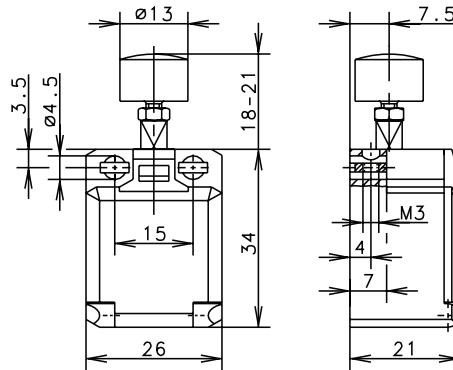

K



R

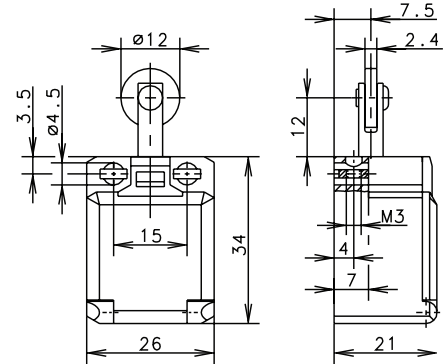


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 600.8107.019
C2-U1Z K




Snap Action

 600.8357.020
C2-SU1Z K




Slow Action

 600.8116.013
C2-U1Z R




Snap Action

 600.8366.014
C2-SU1Z R




2 NC Contacts

 
600.8807.021
C2-A2Z K



 
600.8857.022
C2-SA2Z K



 600.8816.015
C2-SU1Z R



 600.8866.016
C2-SA2Z R



2 NO Contacts

-

-

600.8816.017
C2-E2 R



-

1 NC / 1 NO Contacts Overlapping

-

-

-

-

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage	240V
Maximum Switching Amperage	10A
B10d	6 Million
Mechanical Service Life	3×10^6
Switching Frequency	$\leq 100/\text{min}$
Operating Temperature	-30°C to $+80^\circ\text{C}$
Protection Rating	IP20
Utilization Category	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	240VAC
Approvals	UL, SF, C, US



Slow Action

Snap Action

240V	240V
10A	10A
6 Million	6 Million
3×10^6	3×10^6
$\leq 100/\text{min}$	$\leq 100/\text{min}$
-30°C to $+80^\circ\text{C}$	-30°C to $+80^\circ\text{C}$
IP20	IP20
AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
240VAC	240VAC

