



ENK Series

ENK

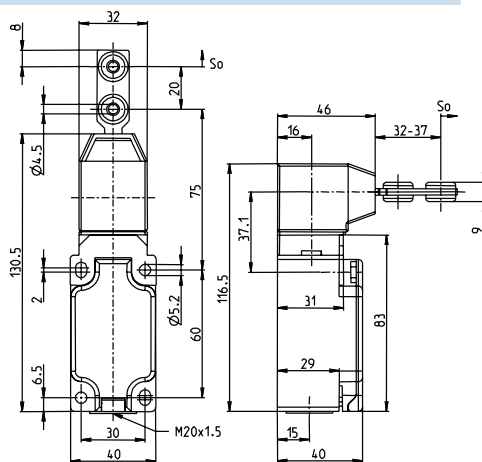


Replacement actuator keys:

A1 ACTUATOR KEY 391.1702.228

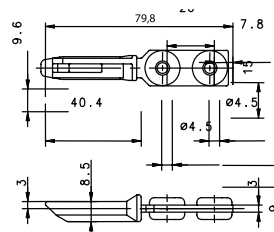


15.7" Minimum Bend Radius

A2 ACTUATOR KEY 391.1702.229

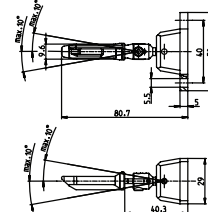


5.9" Minimum Bend Radius

A3 ACTUATOR KEY 391.1702.230

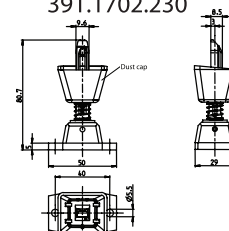

15.7" Minimum Bend Radius

A4 ACTUATOR KEY 391.1702.231

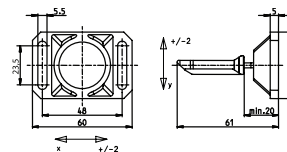


13.8" Minimum Bend Radius

Switching Operation

1 NC / 1 NO Contacts

Slow Action

 601.6619.132
ENK-U1Z VTU




High Activation Force

Radius Activation

1 NC Contacts


2 NC Contacts

 601.6669.133
ENK-A2Z VTU



2 NC / 1 NO Contacts Overlapping

 601.6669.154
ENK-UV15Z VTU



Technical Information

Maximum Switching Voltage

240V

Max. Switching Amps (up to)*

10A

B10d (up to)*

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

Switching Frequency

≤ 30/min

Operating Temperature

-30 °C to +80 °C

Protection Rating

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

250VAC

Approvals

* Depending on switching system - see technical information for details

