
 


FEMALE-FEMALE HERMETIC ADAPTOR
R143.753.000
BULKHEAD PANEL SEAL

Series : TNC

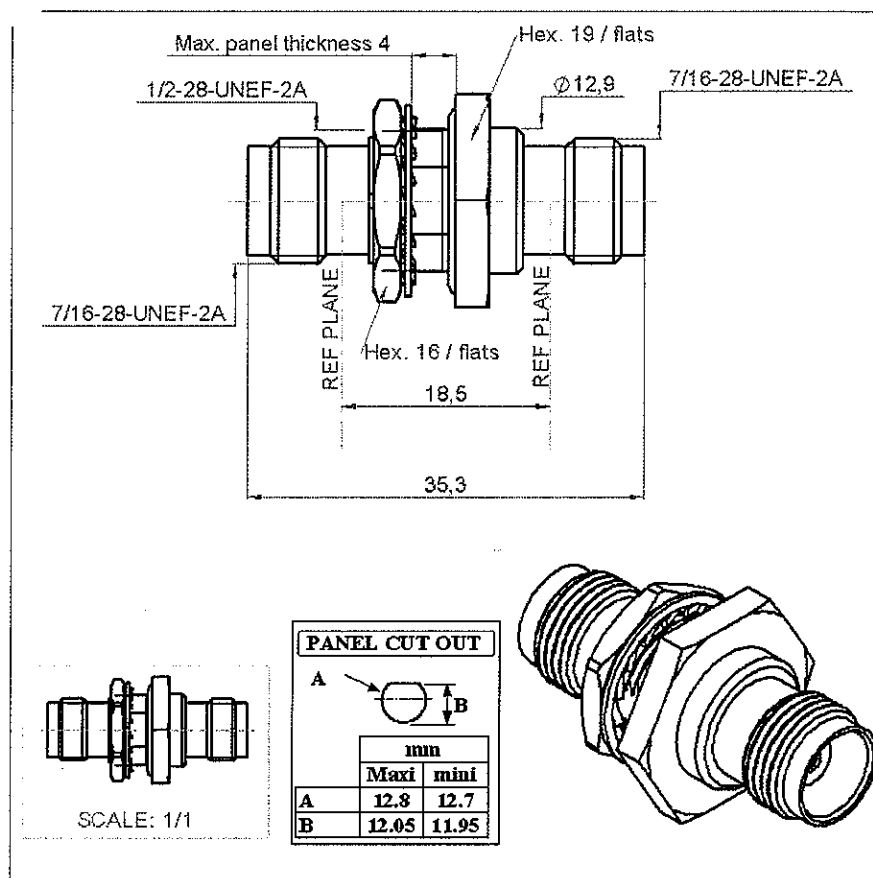

All dimensions are in mm.



COMPONENTS	MATERIALS	PLATINGS (µm)
BODY	BRASS	NICKEL 2
CENTER CONTACT	BERYLLIUM COPPER	GOLD 0.5 OVER NICKEL 2
OUTER CONTACT	-	-
INSULATOR	PTFE+GLASS BEAD	-
GASKET	BLACK FLUOROCARBON	NICKEL 2
OTHERS PARTS	BRASS	-
-	-	-
-	-	-

Issue : 0504 E

In the effort to improve our products, we reserve the right to make changes judged to be necessary.



FEMALE-FEMALE HERMETIC ADAPTOR**R143.753.000****BULKHEAD PANEL SEAL**

Series : TNC

PACKAGING

Standard	Unit	Other
100	'W' option	Contact us

SPECIFICATION**ELECTRICAL CHARACTERISTICS**

Impedance	50	Ω
Frequency	0-11	GHz
VSWR	1.45 + 0.000	x F(GHz) Maxi
Insertion loss	0.07	$\sqrt{F}$ (GHz) dB Maxi
RF leakage	- (57	- F(GHz)) dB Maxi
Voltage rating	500	Veff Maxi
Dielectric withstanding voltage	1500	Veff mini
Insulation resistance	5000	M Ω mini

ENVIRONMENTAL

Operating temperature	-65/+100	$^{\circ}$ C
Hermetic seal	10-8	Atm.cm ³ /s
Panel leakage	NA	

OTHERS CHARACTERISTICS

Assembly instruction

Others :

MECHANICAL CHARACTERISTICS

Center contact retention	
Axial force – Mating end	26 N mini
Axial force – Opposite end	26 N mini
Torque	NA N.cm mini
Recommended torque	
Mating	NA N.cm
Panel nut	260 N.cm
Mating life	500 Cycles mini
Weight	23.232 g

Issue : 0504 E

In the effort to improve our products, we reserve the right to make changes judged to be necessary.

