


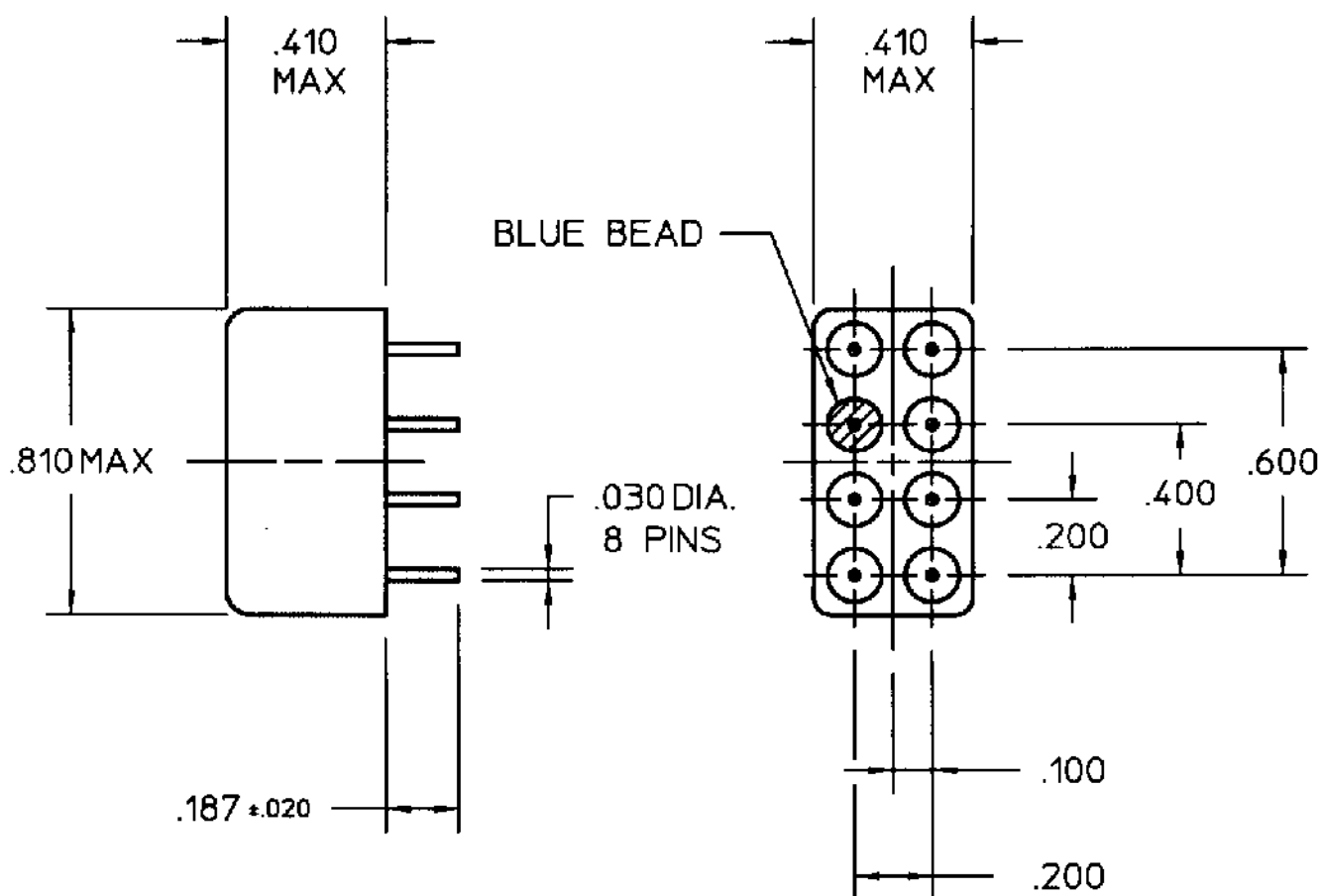


REV. 0
DCO 15131

COIL: @ +25 °C
 RESISTANCE 320 OHMS ± 10%
 NOMINAL VOLTAGE 12-15 VDC
 MUST OPERATE 6.8 VDC
 MUST RELEASE 0.68 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
 RELEASE TIME 4.0 MS MAX
 CONTACT BOUNCE 2.0 MS MAX

CUSTOMER DATA SHEET

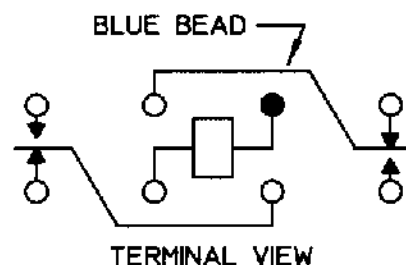

CONTACT RATING: LOW LEVEL TO
 2 AMPS 28 VDC RESISTIVE 100,000
 OPERATIONS

DR. R.B. 2/22/99 CK. Galt 2-22-99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO.

TYPE "HFW" RELAY

HFW1201B00