



SPECIFICATIONS

PARAMETERS	VALUES	UNITS
RATED VOLTAGE	12	Vdc
OPERATING VOLTAGE RANGE	9 ~ 16	Vdc
RATED CURRENT (MAX)	35	mA
MINIMUM SPL @ 10 CM	90	dBA
RESONANT FREQUENCY	5,000 ± 500	Hz
tone or pulse rate	CONTINUOUS	0 pulse /sec
OPERATING TEMPERATURE	-30 ~ +85	°C
STORAGE TEMPERATURE	-40 ~ +95	°C
HOUSING MATERIAL	PBT	-
TERMINAL MATERIAL	Au PLATED BRASS	-
WEIGHT	2.5	grams

THIS DOCUMENT CONTAINS DATA PROPRIETARY
TO PROJECTS UNLIMITED, INC. ANY USE OR
REPRODUCTION, IN ANY FORM, WITHOUT PRIOR
WRITTEN PERMISSION OF PROJECTS UNLIMITED,
INC. IS PROHIBITED.
©2003, Projects Unlimited Inc.

REVISION HISTORY	
------------------	--

LTR	DESCRIPTION	DATE	APPROVED
-	RELEASED FROM ENGINEERING	10/08/2007	
A	REVISED TO INVENTOR 3-D DRAWING TEMPLATE	12/5/2007	B.R.

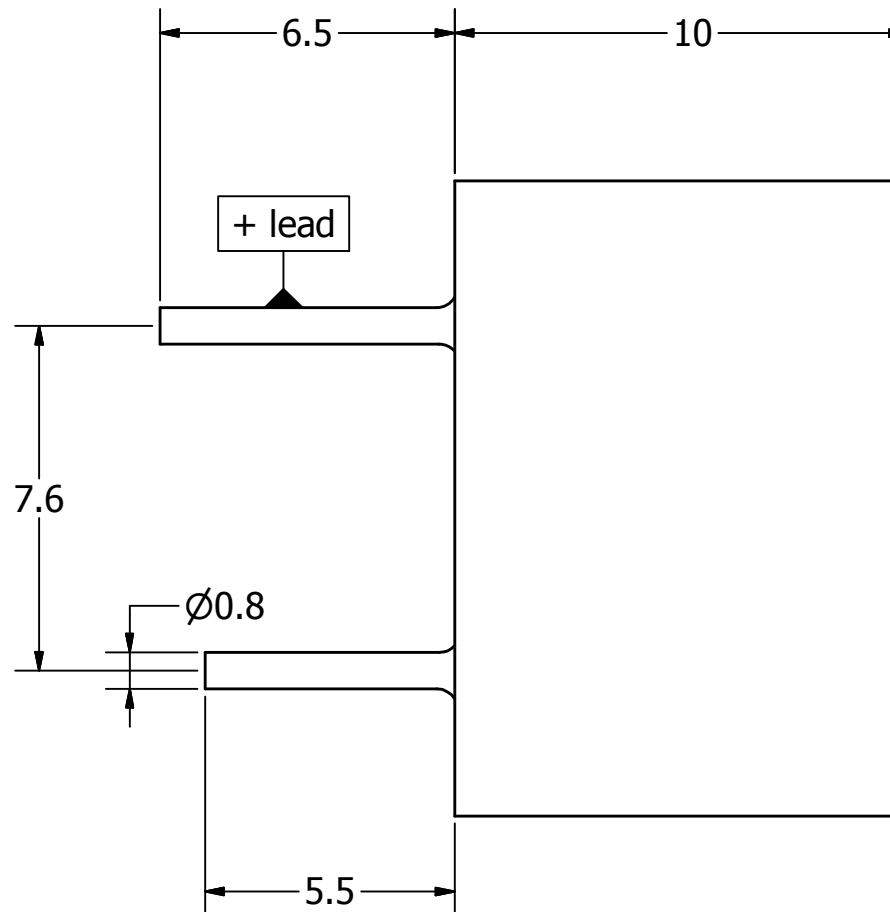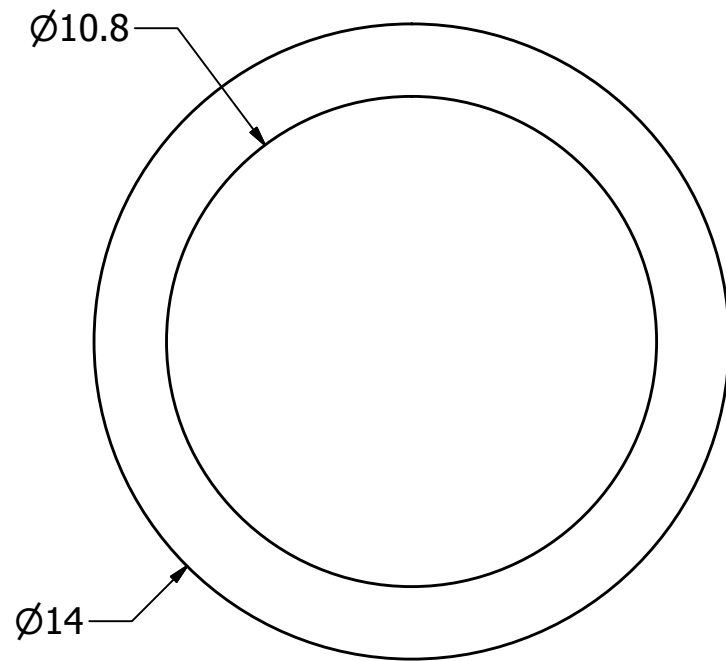

NOTES:

1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. SPECIFICATIONS SUBJECT TO CHANGE OR WITHDRAWL WITHOUT NOTICE.
3. THIS PART IS RoHS 2002/95/EC COMPLIANT.
4. PART IS IP67 RATED.

UNLESS OTHERWISE SPECIFIED: DIMENSIONS ARE IN MILLIMETERS, TOLERANCES ARE ±0.5 AND ANGLES ARE ±3°.	SIZE A3	Designed by	Date	Checked by	Date	Approved by	Date	Drawn Date
		J.D.	9/30/2007	B.R.	10/8/2007	R.W.	10/8/2007	12/5/2007
 pui audio TM inc a projects unlimited company		AI-1450-TWT-WP-R						
		Indicator					Edition -	Sheet 1 / 1
AI-1450-TWT-WP-R.idw								