

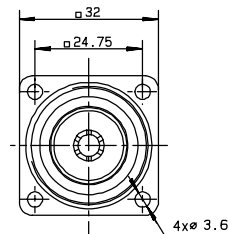
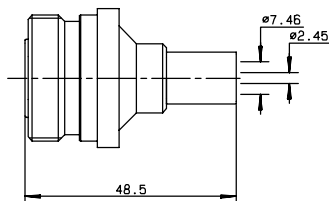


STRAIGHT SQUARE FLANGE JACK CRIMP TYPE FOR FLEXIBLE CABLES

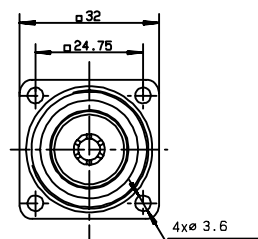


cable	part number	center cont.	assembly	panel	finish	note
10/50 S + D	R185 274 000	yes	M05	P01	Silver+BBR	RG 213 & RG 393
11/50 D	R185 277 000	yes	M05	P01		

STRAIGHT SQUARE JACK CLAMP TYPE FOR FLEXIBLE CABLES

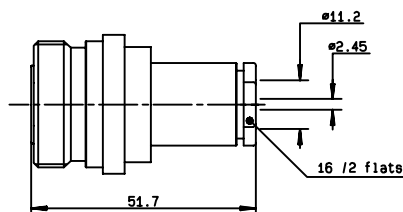


cable	part number	capt. center cont.	assembly	panel	finish
10 + 11/50 D	R185 260 000	yes	M01	P01	Silver+BBR

 Note : standard packaging = 20 pieces. For unit packaging, add "W" after the P/N.




STRAIGHT SQUARE FLANGE JACK EZ FIT TYPE FOR CORRUGATED CABLES

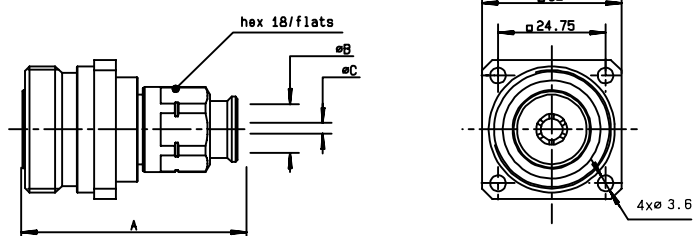

cable	part number	dimension			capt. center cont.	assembly	panel	finish
		A	B	C				
1/4" superflexible corrugated	R185 265 200	49.45	7.95	4.7	yes	M02	P01	Silver+BBR
1/2" superflexible corrugated	R185 266 200	50	14	8.8	yes	M02	P01	
3/8" superflexible corrugated	R185 267 200	50	11	7.1	yes	M02	P01	

STRAIGHT SQUARE FLANGE JACK SOLDER TYPE FOR SEMI RIGID CABLES

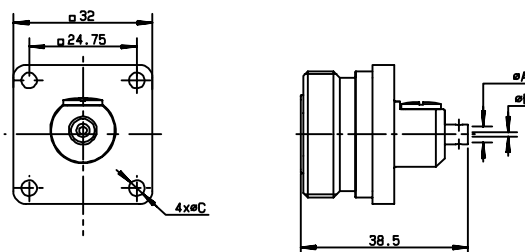

cable	part number	capt. center cont.	dimensions			assembly	panel	finish
			A	B	C			
.141"	R185 252 000•	yes	3.65	1.05	3.6	M06	P01	Silver+BBR
.250"	R185 254 000•	yes	6.45	1.75	3.6	M06	P01	

- Manufactured upon request

Note : standard packaging = 20 pieces. For unit packaging, add "W" after the P/N.