

**Customer Part:**
**Description**

- 2 x 1.6mm SMD crystal  
Ceramic package with a seam sealed metal lid, hermetically sealed
- Model IQXC-42
- Model Issue number 1

**Frequency Parameters**

- Frequency 27.0MHz
- Frequency Tolerance  $\pm 15.00\text{ppm}$
- Frequency Stability  $\pm 20.00\text{ppm}$
- Operating Temperature Range  $-40.00$  to  $85.00^{\circ}\text{C}$
- Overtone Order Fundamental
- Ageing  $\pm 3\text{ppm}$  max per year @  $25^{\circ}\text{C}$

**Electrical Parameters**

- Load Capacitance (CL) 10.00pF
- Shunt Capacitance (C0) 3pF max
- Drive Level 100 $\mu\text{W}$  max
- ESR 100.00 $\Omega$  max

**Environmental Parameters**

- Shock: IEC 60068-2-27: 1000G, 1ms, 3 times in each of 3 mutually perpendicular planes
- Vibration: IEC 60068-2-6: 1.5mm amplitude, 10Hz-55Hz, 1min in 3 mutually perpendicular planes, duration 2hrs each plane (total 6hrs)
- Storage Temperature Range:  $-55$  to  $125^{\circ}\text{C}$

**Manufacturing Details**

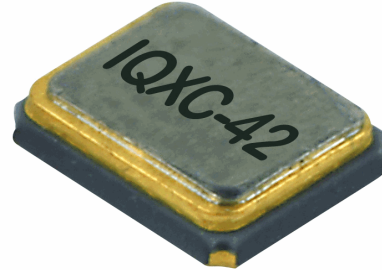
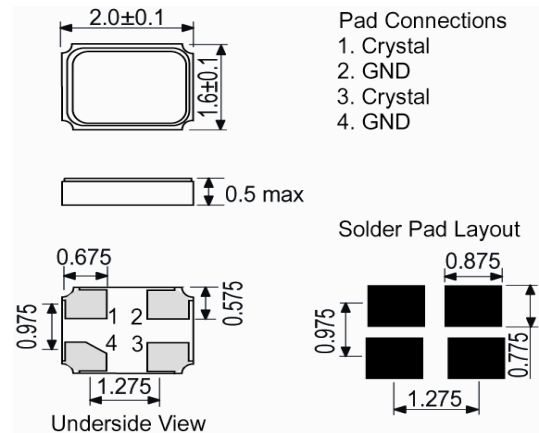
- RoHS Terminations NiAu
- RoHS Reflow Temp 260degC 10s

**Compliance**

- RoHS Status (2015/863/EU) Compliant
- REACH Status Compliant
- MSL Rating (JDEC-STD-033): Not Applicable

**Packaging Details**

- Pack Style: Reel Tape & reel in accordance with EIA-481-D  
Pack Size: 1,000
- *Alternative packing option available*


**Outline (mm)**

**Sales Office Contact Details:**

UK: +44 (0)1460 270200  
Germany: 0800 1808 443

France: 0800 901 383  
USA: +1.760.318.2824

Email: [info@iqdfrequencyproducts.com](mailto:info@iqdfrequencyproducts.com)  
Web: [www.iqdfrequencyproducts.com](http://www.iqdfrequencyproducts.com)