

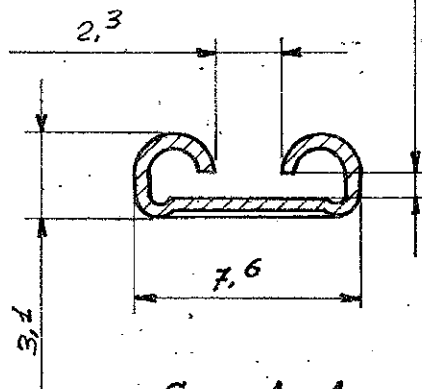


C-280357 NUMBER	ADATTO PER APPLIC. STANDARD (FOR STANDARD APPLICATOR)		ADATTO PER MINI APPLICATOR (FOR MINI APPLICATOR)		
	N° PART. (PART/NUMBER)	MATERIALE/FINITURA (MATERIAL/FINISH)	N° PART. (PART/NUMBER)	MATERIALE/FINITURA (MATERIAL/FINISH)	
	280357-1	BRONZO FOSFOROSO (PHOSPH. BRASS)	280428-1	BRONZO FOSFOROSO (PHOSPH. BRASS)	OBSOLETE
	280357-2	BRONZO FOSF. STAGNATO (TIN PL. PH. BR.)	280428-2	BRONZO FOSF. STAGNATO (TIN PL. PH. BR.)	
	280357-3	OTTONE (BRASS)	280428-3	OTTONE (BRASS)	OBSOLETE
	280357-4	OTTONE STAGNATO (FIN PL. BRASS)	280428-4	OTTONE STAGNATO (FIN PL. BRASS)	
OBSOLETE			280428-4	OTTONE STAGNATO (TIN PL. BRASS)	OBSOLETE

Adatto per linguetta di sp. 0.8
(TO FIT 0.8 mm TAB THK)

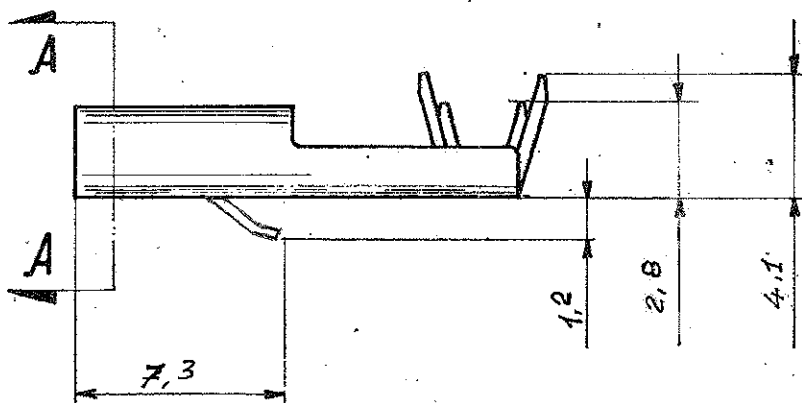

Sez. A-A

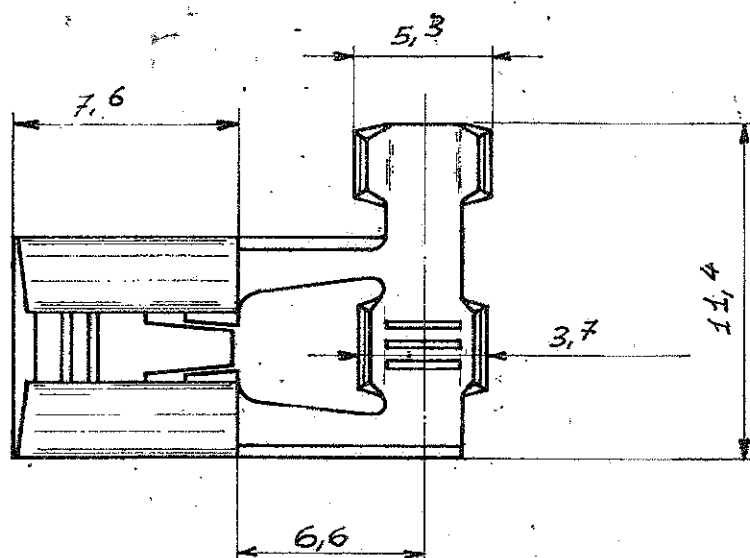

© 1973 BY AMP INCORPORATED. ALL RIGHTS RESERVED. AMP PRODUCTS COVERED BY PATENTS AND/OR PATENTS PENDING.

CUSTOMER COPY
REFERENCE ONLY

MATERIAL AND FINISH

VEDERE TABELLA
(SEE TABLE)

TE

TE Connectivity

CLASS .250 SERIES

WIRE RANGE - INSULATION
0.5 - 1.5 mm² | 3.3 Ø MAX

TYPE F. F.

TOLERANCE EXCEPT
AS NOTED
3/0.4

SCALE

4:1

LOC

I

NO

A

C-280357

REV

N2

NAME

.250 SERIES FLAG FASTEN-ON REC.

N2 REVISED PER ECR-17-013054

BDA

TD

22NOV2017

LTR

REVISION RECORD

DR

CHK

DATE

DR

9-1-73

DE

18/12/74

CHK

18/12/74

APP

DIMENSIONS IN MM. DO NOT SCALE PRINT

PRINT DIST