

# AUTO LINK PAL FUSES - 2935

**RoHS**



## Description


PAL fuses are commonly found on many Japanese and domestic built vehicles.

## Ratings

| Part Number | Current Rating (A) | Body Color  |
|-------------|--------------------|-------------|
| 0293525._   | 25                 | LIGHT BROWN |
| 0293530._   | 30                 | LIGHT GREEN |
| 0293545._   | 45                 | RED         |
| 0293565._   | 65                 | BLACK       |
| 0293575._   | 75                 | GRAY        |

## Dimensions (25A - 30A)

Dimensions in mm

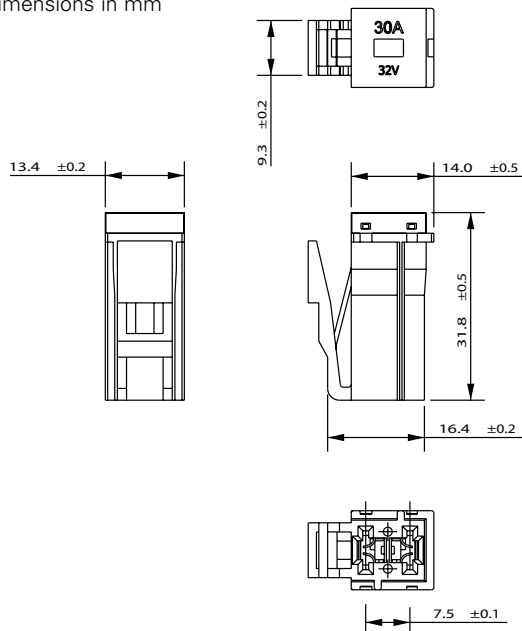

## Specifications

Voltage Rating: 32 VDC  
Current Cycling: 24°C  
The fuses satisfy the performance requirements after 50% of the rated current is applied for 10,000 cycles. Each cycle consists of an interrupted current with the pattern of 5 minutes ON and 10 minutes OFF.  
Operating Temperature Range: -40°C to +125°C

Complies with JASO 0612

## Ordering Information

| Part Number | Package Size |
|-------------|--------------|
| 02935xx.H   | 100          |
| 02935xx.U   | 500          |
| 02935xx.MXJ | 1000         |

## Time-Current Characteristics

| % of Rating | Opening Time Min / Max (s) |            |
|-------------|----------------------------|------------|
|             | 25A - 30A                  | 45A - 75A  |
| 110         | - / -                      | 14,400 s   |
| 150         | - / -                      | 100 s      |
| 200         | 5 s / 70 s                 | 2 s / 60 s |
| 300         | - / 6 s                    | - / 5 s    |
| 600         | - / 3 s                    | - / 2 s    |

## Dimensions (45A - 75A)

Dimensions in mm

