



## 2 · ROW

### Cable or Board to Crimp Removable


.075"

**RM2**


10 thru 100 Contacts

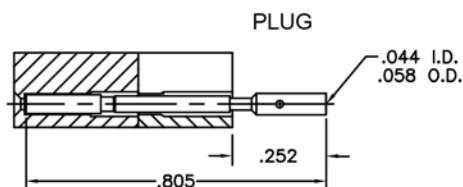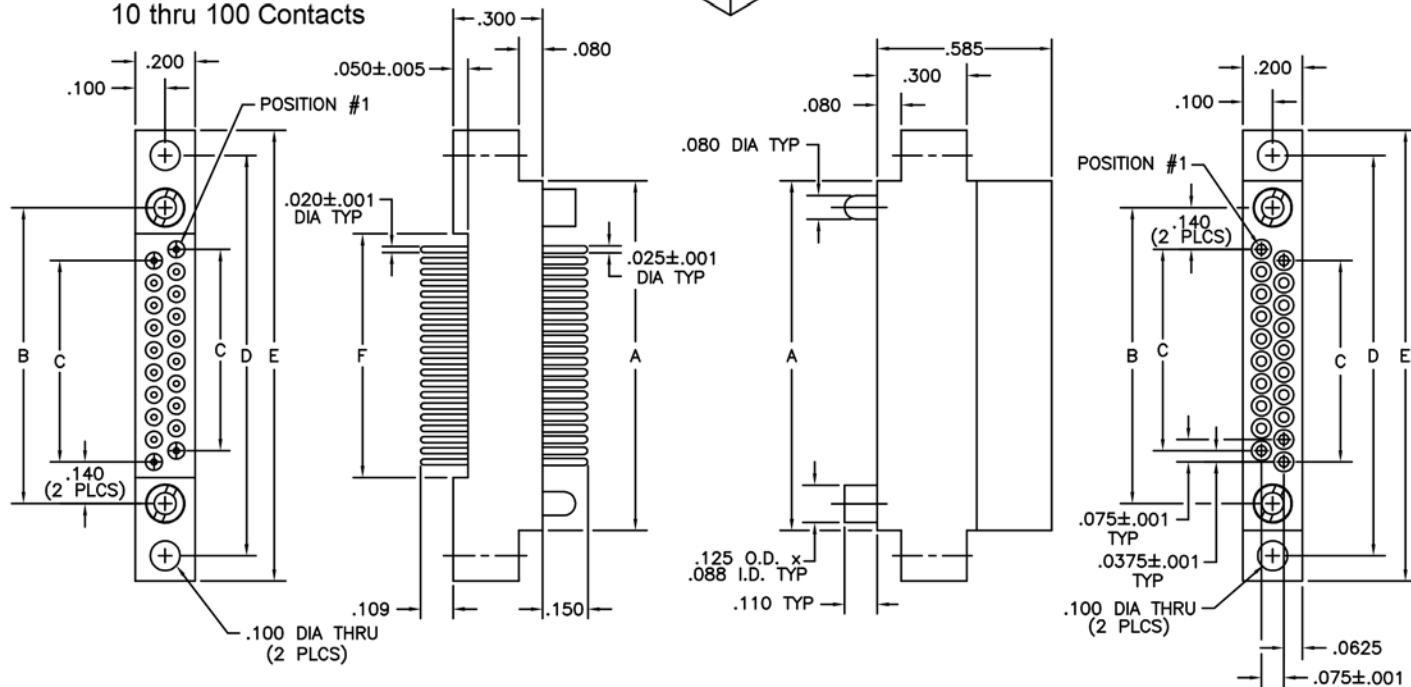

20-22 AWG

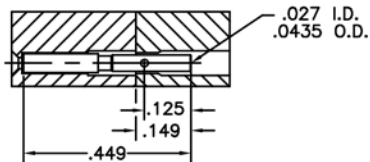

24-26 AWG

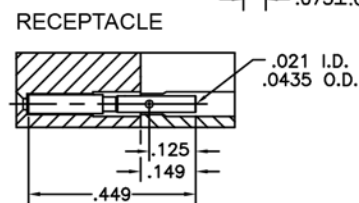

28-30 AWG

NOTE:

When using crimp contacts with 20 gage barrel, barrel must be cut off prior to removing contact from connector body.

| CRIMP REMOVABLE CONTACTS |                    |
|--------------------------|--------------------|
| SIZE                     | PART NUMBER        |
| 20-22 AWG                | RM200-000-571-0000 |
| 24-26 AWG                | RM200-000-581-0000 |
| 28-30 AWG                | RM200-000-591-0000 |

| DIMENSIONS |       |       |       |       |       |       |
|------------|-------|-------|-------|-------|-------|-------|
| SIZE       | A     | B     | C     | D     | E     | F     |
| 10         | .797  | .617  | .300  | .967  | 1.137 | .442  |
| 20         | 1.172 | .992  | .675  | 1.342 | 1.512 | .817  |
| 30         | 1.547 | 1.367 | 1.050 | 1.717 | 1.887 | 1.192 |
| 40         | 1.922 | 1.742 | 1.425 | 2.092 | 2.262 | 1.567 |
| 50         | 2.297 | 2.117 | 1.800 | 2.467 | 2.637 | 1.942 |
| 60         | 2.672 | 2.492 | 2.175 | 2.842 | 3.012 | 2.317 |
| 70         | 3.047 | 2.867 | 2.550 | 3.217 | 3.387 | 2.692 |
| 80         | 3.422 | 3.242 | 2.925 | 3.592 | 3.762 | 3.067 |
| 90         | 3.797 | 3.617 | 3.300 | 3.967 | 4.137 | 3.442 |
| 100        | 4.172 | 3.992 | 3.675 | 4.342 | 4.512 | 3.817 |