


## ENK Series

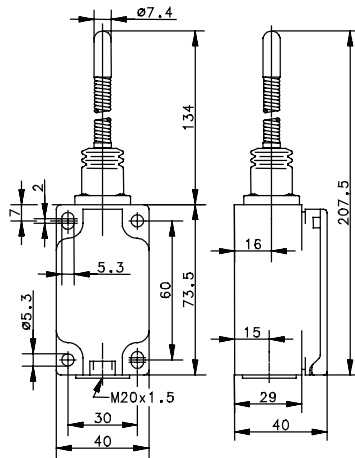

**FF**



 
### Switching Operation

**1 NC / 1 NO Contacts**

### Slow Action

### Snap Action

**608.1190.045**  
ENK-SU1 FF



**2 NC Contacts**

-

-

**2 NO Contacts**

-

-

**1 NC / 1 NO Contacts  
Overlapping**

-

-

**Replacement actuator:**

**391.8400.662**

### Technical Information

### Slow Action

### Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)\*

10A

10A

B10d (up to)\*

20 Million

20 Million

Mechanical Service Life (up to)\*

10 x 10<sup>6</sup>

10 x 10<sup>6</sup>

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)\*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals

\* Depending on switching system - see technical information for details

