


5

4

3

2

1

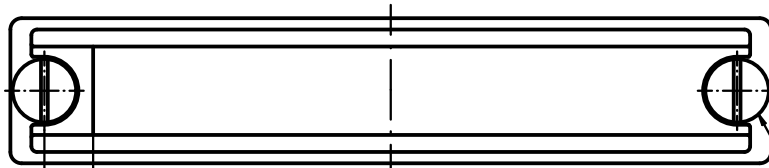

Slotted pan head tapping screws
DIN 7971-ST 2,9x6,5-F
screwing torque=35Ncm +/-5Ncm

4,3

67,1

Slotted pan head tapping screws
DIN 7971-ST 2,2 x 9,5-F
Maximum screwing torque= 0,25 mN

Min. 5,75
Max. 11,6

20

11,6

15,8

11,9

4,1

55,3

61,1



All Dim. in mm
Orig. Size DIN A 4

D-Sub, hood 50 poles
for spring or slide
locking, side cable entry

Maßstab/
Scale

1,5:1

				Dat.	Name
			Detail.	28/03/02	CV
			Insp.	25-MAY-11	JMDV
EC03223	25-MAY-11	SD	Stand.		
34886	26/02/08	PK			
29760	28/03/02	CV			
Mod.	Dat.	Name			

HARTING EURL
F-95972 Paris



TB 09 67 050 051X

Sub.

Blatt/ Page

1 / 1

09 67 050 0513	Thermoplastic metallized
09 67 050 0511	Thermoplastic grey RAL 7032
Part number	Material