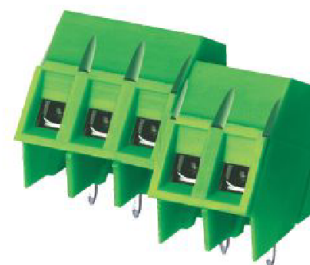
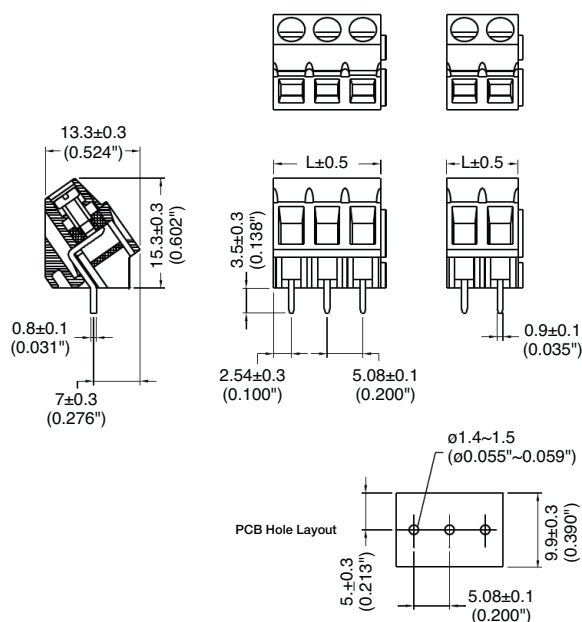


EM3228 Series**EuroMag Terminal Blocks**

35° Angle; 5.08 Centers; Modular

SPECIFICATIONS**Rating:** 16A, 300V**Center Spacing:** 0.20" (5.08mm)**Wire Range:** #12-26 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Brass Tin-Plated**Cage Material:** Brass, Nickel-Plated**Screw Size:** M2.6 Zinc-Plated Steel**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Torque Rating:** 5 lb-in.**Recommended PCB Hole Diameters:** 0.055" (1.40mm)**Construction:** Modular design features dovetails for interlocking to achieve longer lengths**Agency Information:** cULus File E62622; CE Certified

EM322805

Dimensions - mm (in)

Poles	L (mm)	Poles	L (mm)
2	10.16	14	72.12
3	15.24	15	76.20
4	20.32	16	81.28
5	25.40	17	86.36
6	30.48	18	91.44
7	35.56	19	96.52
8	40.64	20	101.60
9	45.72	21	106.68
10	50.80	22	111.76
11	55.88	23	116.84
12	60.96	24	121.92
13	66.04		

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM3228

□□

02 to 24