


REV. 1
DCO 142816

COIL: @ 25°C	
RESISTANCE	390 OHMS ±20%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	8.4 VDC
MUST RELEASE	

ENVIRONMENT:	
VIBRATION	10 CPS TO 500 CPS @ 10 g's
SHOCK	30 g's 6 MS. DURATION
TEMPERATURE	-55 °C TO +85 °C
NOTES:	OPERATE TIME 4 MS MAX
	RELEASE TIME 3 MS MAX

CUSTOMER DATA SHEET

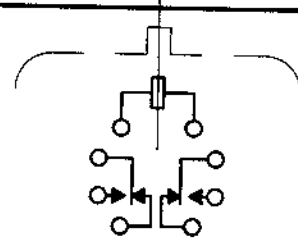

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 2/14/01 CK.3/A/01/003

CII Technologies
advanced control electronic solutions

CUST. C. I. I. STD.
CUST. NO. REV.

MW6 RELAY
MICROWAVE

MW6-12A