


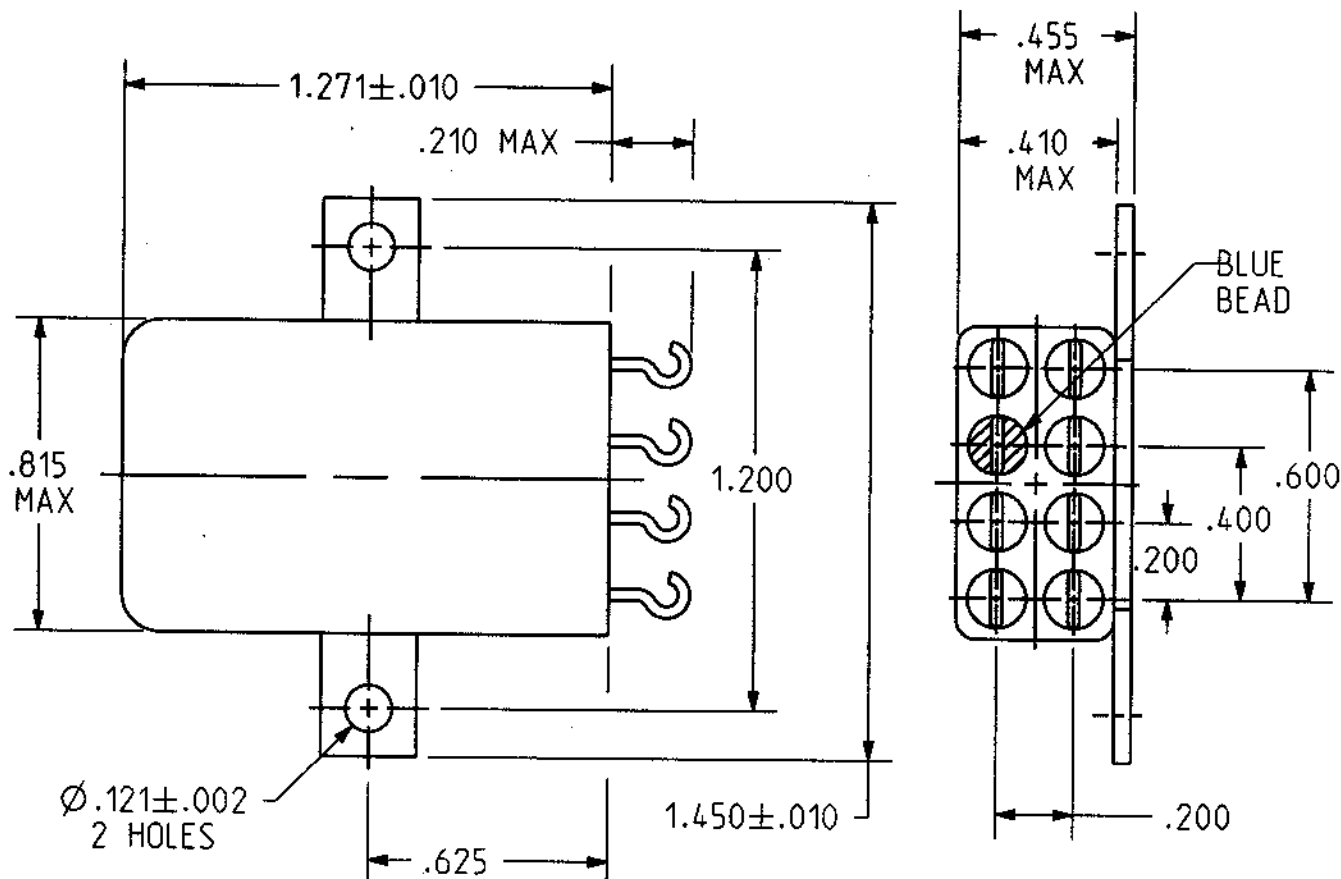

REV. 0
DCO 170668

COIL: @ 25°C
RESISTANCE 5000 OHMS: $\pm 10\%$
NOMINAL VOLTAGE 6.0 mADC
MUST OPERATE 2.8 mADC
MUST RELEASE 1.4 mADC MAX 0.30 mADC MIN

ENVIRONMENT:
VIBRATION 10 Hz TO 2000 Hz @ 15 g's
SHOCK 100 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C


NOTES: OPERATE TIME 15 MS MAX.
RELEASE TIME 10 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUST. QPL
CUST. NO. M5757/13-141 REV.

3SAT RELAY

CUSTOMER DATA SHEET

BLUE BEAD

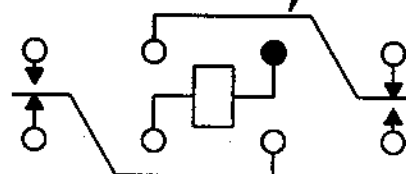

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. ASB 11 JUN 02 CK. 6/11/02

CII Technologies
advanced control electronic solutions

3SAT1358A2