


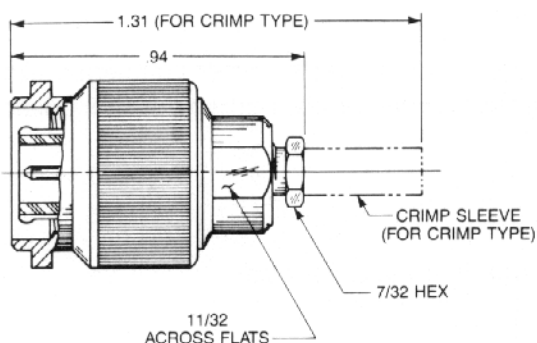

Straight Plug For Flexible Or Semi-Rigid Cable

Clamp type for flexible cable:

6000-1051-0XX (Gold plated)

6000-7051-0XX (Nickel plated)

Crimp type for flexible cable:


6000-1071-0XX (Gold plated)

6000-7071-0XX (Nickel plated)

Solder-clamp for semi-rigid cable:

6000-1041-0XX (Gold plated)

6000-7041-0XX (Nickel plated)

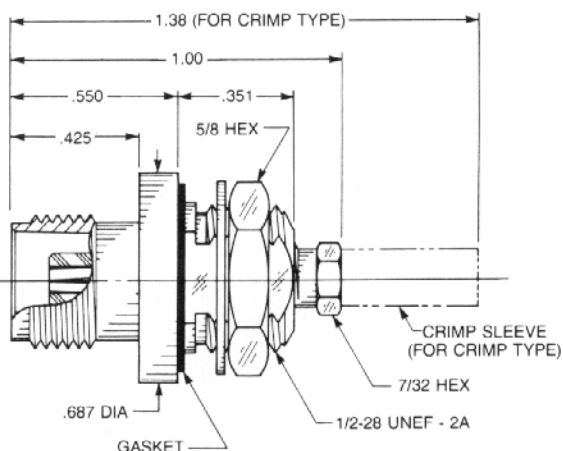

Bulkhead Jack Front Mount

Clamp type for flexible cable:

6002-1051-0XX (Gold plated)

6002-7051-0XX (Nickel plated)

Crimp type for flexible cable:


6002-1071-0XX (Gold plated)

6002-7071-0XX (Nickel plated)

Solder-clamp for semi-rigid cable:

6002-1041-0XX (Gold plated)

6002-7041-0XX (Nickel plated)

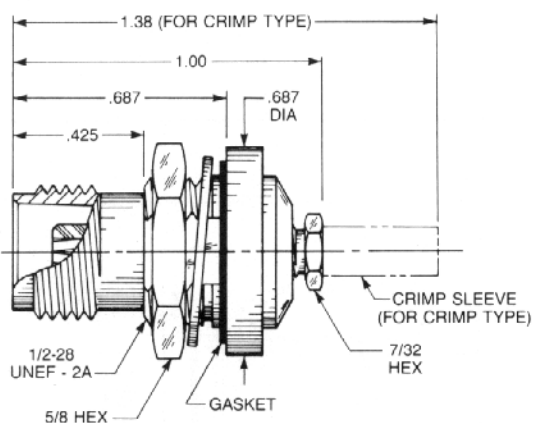

Bulkhead Jack Rear Mount

Clamp type for flexible cable:

6001-1051-0XX (Gold plated)

6001-7051-0XX (Nickel plated)

Crimp type for flexible cable:

6001-1071-0XX (Gold plated)

6001-7071-0XX (Nickel plated)

Solder-clamp for semi-rigid cable:

6001-1041-0XX (Gold plated)

6001-7041-0XX (Nickel plated)

Substitute the appropriate cable group for 'XX':

02	RG178, RG196, M17/93, M17/169	09	.141" semi-rigid, RG402, M17/130
03	RG174, RG179, RG316, M17/113, M17/119, M17/172, M17/173	10	.085" semi-rigid, RG405, M17/133
05	RG178DS, RG196DS	19	RG174DS, RG316DS, M17/152, Times RD316