
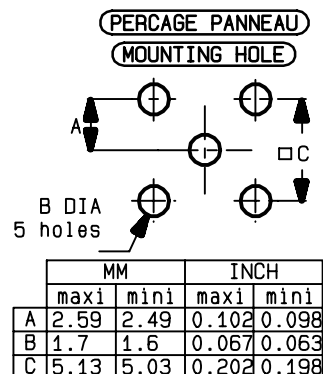


RIGHT ANGLE RECEPTACLE FOR PCB SOLDER LEGS - PACK.100

R128.665.820

SERIES BMA COM

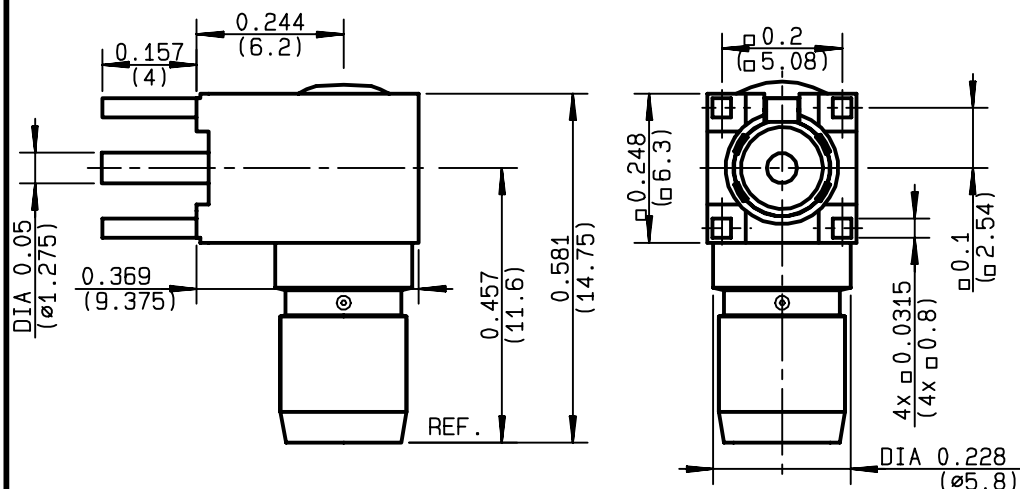

NOMINAL IMPEDANCE	50	Ω
FREQUENCY RANGE	0-22	GHz
TEMPERATURE RATING	-65/+125	°C
V.S.W.R	1.25* + 0 x F(GHz)	Maxi
RF INSERTION LOSS	0.08 √F(GHz)	dB Maxi
VOLTAGE RATING	350	Veff Maxi
DIELECTRIC WITHSTANDING VOLTAGE	1000	Veff Mini
INSULATION RESISTANCE	5000	MΩMini
HERMETIC SEAL	NA	Atm.cm ³ /s
LEAKAGE (pressurized only)	NA	
MECHANICAL DURABILITY	500	Cycles
WEIGHT	3.15	gr
SPECIFICATION	* R.O.S 1.25 MAXI 0-10 GHz * V.S.W.R 1.25 MAX 0-10 GHz	

CABLES :

OTHERS CHARACTERISTICS

* de 0 -10 Ghz

CABLE RETENTION	NA	N Mini
CENTER CONTACT RETENTION		
Axial force - mating end	18	N Mini
Axial force - opposite end	18	N Mini
Torque	NA	cm.N Mini
RECOMMENDED TORQUES		
Mating	NA	cm.N
Panel nut	NA	cm.N
Clamp nut	NA	cm.N

CONNECTOR PARTS. MATERIALS

BODY	BRASS
OUTER CONTACT	
CENTER CONTACT	BRASS
INSULATOR	PTFE
GASKET	
OTHERS PIECES	BRASS

FINISH (all values are given in micrometers)

GOLD 0.2 OVER NICKEL 2
GOLD 1.3 OVER COPPER 2
-
GOLD 0.2 OVER NICKEL 2

BAFFERT

ISSUE
9926A00

CREATION DATE
23/06/1997

FILE PART-NUMBER
EPC96-06



RADIALL®

The information given here is subject to change without notice.
Design changes may be in order to improve the product.

Connect to the future