

R 15-AG

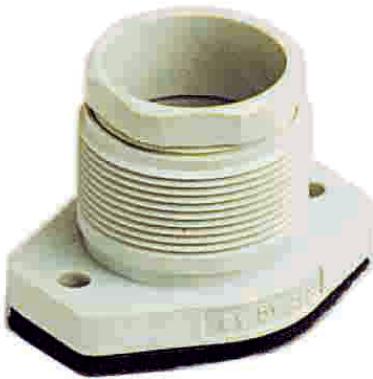


Image is for illustration purposes only. Please refer to product description.

Part number	09 15 000 0301
Specification	R 15-AG
HARTING eCatalogue	https://b2b.harting.com/09150000301

Identification

Category	Hoods/Housings
Series	R 15
Type of hood/housing	Bulkhead mounted housing

Version

Locking type	Screw locking
--------------	---------------

Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65

Material properties

Material (hood/housing)	Polycarbonate (PC)
Material (seal)	NBR
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Commercial data

Packaging size	10
----------------	----

Commercial data

Net weight	10 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440224 Shell for circular connectors