 


Miniature Neon Indicators

WITH BUILT-IN RESISTOR



T-3 1/4
B1A (NE-51)
B2A (NE-51H)
MINIATURE BAYONET BASE


See lamp ratings
on page L.

Recognized under the component
program of Underwriters'
Laboratories Inc.
75W., 125V.




FOR REAR MOUNTING IN 9/16" CLEARANCE HOLE

For materials and finishes of products in this group, see page 51D.

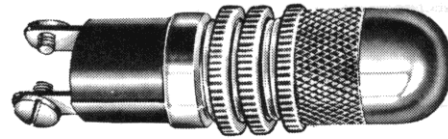

17-1363-0931-215
Stovepipe lens

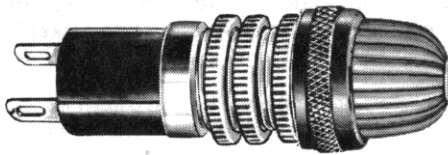

70-0463-1191-215
Stovepipe lens

17 SERIES
70 SERIES

WITH SCREW ON-LENS CAPS

solder terminals	screw terminals

BASE PART NUMBERS		105-125VAC-DC* 110-125VAC†	70-0408-11-245 70-0463-11-215	70-1308-11-245 70-1363-11-215
CAP PART NUMBERS		VOLTAGES	COMPLETE ASSEMBLY PART NUMBERS	
STOVEPIPE 17-0931-200 transparent 17-0991-200 internal fluting		105-125V AC-DC 110-125 VAC 105-125V AC-DC 110-125 VAC	17-0408-0931-245 17-0463-0931-215 17-0408-0991-245 17-0463-0991-215	17-1308-0931-245 17-1363-0931-215 17-1308-0991-245 17-1363-0991-215
STOVEPIPE ■ 70-1131-200 transparent ■ 70-1191-200 internal fluting		105-125V AC-DC 110-125 VAC 105-125V AC-DC 110-125 VAC	■ 70-0408-1131-245 ■ 70-0463-1131-215 ■ 70-0408-1191-245 ■ 70-0463-1191-215	■ 70-1308-1131-245 ■ 70-1363-1131-215 ■ 70-1308-1191-245 ■ 70-1363-1191-215

■ To specify white translucent color, change so much of the catalog number that reads from -1131- to -0935-; from -1191- to -0995-. Example: 70-0408-0935-245.

* Standard brightness
† High brightness

Part numbers listed in this catalog designate products with RED lens.
For ordering lens colors other than red, consult chart on page 2D.

Order complete with lamp to be assured of receiving the
indicator light and correct lamp together for immediate use.