



ENK Series

AHS-V (Form A)

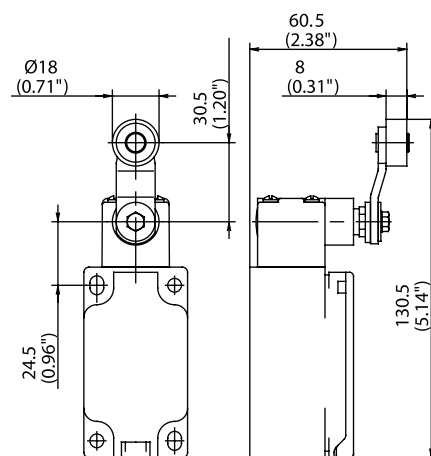

AV

 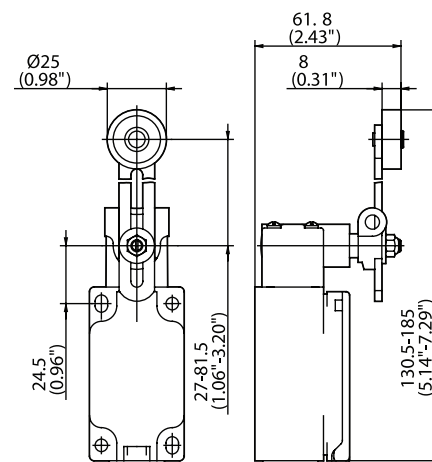


Switching Operation

1 NC / 1 NO Contacts


Slow Action

608.1135.003
ENK-U1Z AHS-V




Snap Action

 608.1185.009
ENK-SU1Z AHS-V




Slow Action

 608.1136.012
ENK-U1 AV




Snap Action

 608.1186.018
ENK-SU1 AV



2 NC Contacts

 608.1835.323
ENK-A2Z AHS-V



-

-

-

2 NO Contacts

-

 
-

-

-

1 NC / 1 NO Contacts Overlapping

608.1335.006
ENK-UV1Z AHS-V



-

-

-

Replacement actuator:

391.8350.737

391.8360.738

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

3 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals

* Depending on switching system - see technical information for details



Special features/variants (on request)

- Available with black enclosure
- With 50 mm diameter rubber roller
- 3 NC contacts possible

Special features/variants (on request)

- Available with different lever lengths
- With 50 mm diameter rubber roller

Drawing dimensions in mm