


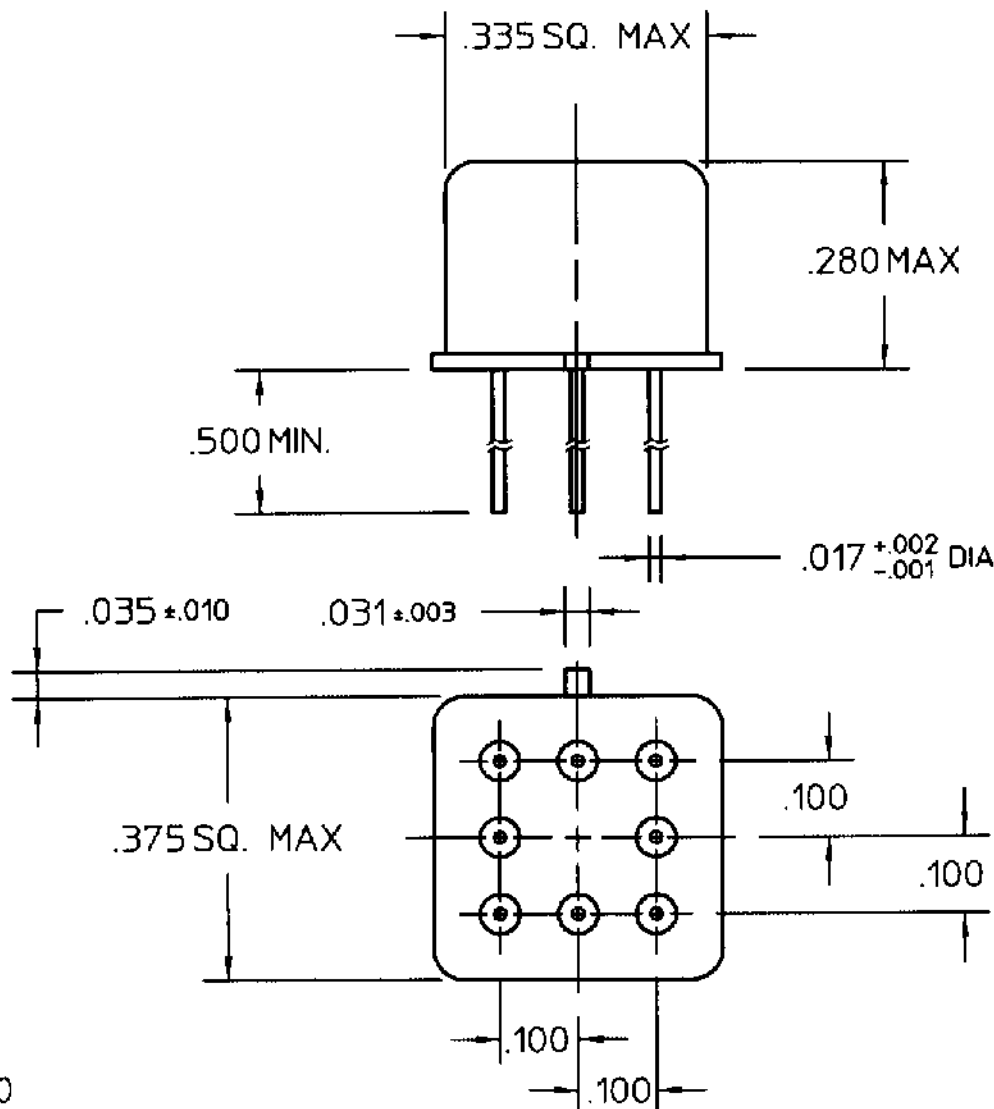

REV. 0
DCO 141811


COIL: @ 25°C
RESISTANCE 1560 OHMS $\pm$ 10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 14.2 VDC
MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX
RELEASE TIME 4.0 MS MAX
CONTACT STABILIZATION 2.5 MS MAX

CUSTOMER DATA SHEET

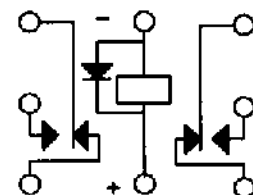

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 2/23/00 JCK 2/23/00

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. OPL
CUST. NO. M39016/18-036P REV.

'JMGAD' RELAY

JMGACD-26P