


SERIES 76 and 78


SPDT

FEATURES


- Raised and Recessed Rocker, and Toggle Actuated Styles
- SPDT with a Common Pole, or SPDT with 2 Isolated Circuits
- Spring and Ball Contact
- Top Tape Seal Option for Most Styles
- RoHS Compliant

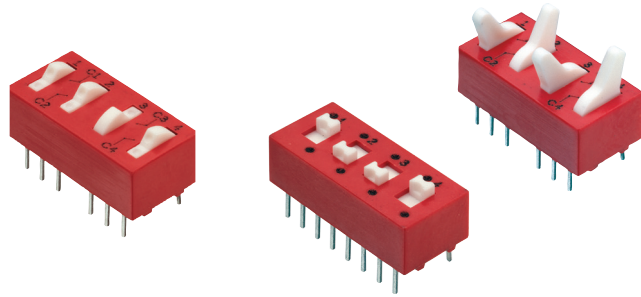


DIMENSIONS: Series 76 in inches (and millimeters)

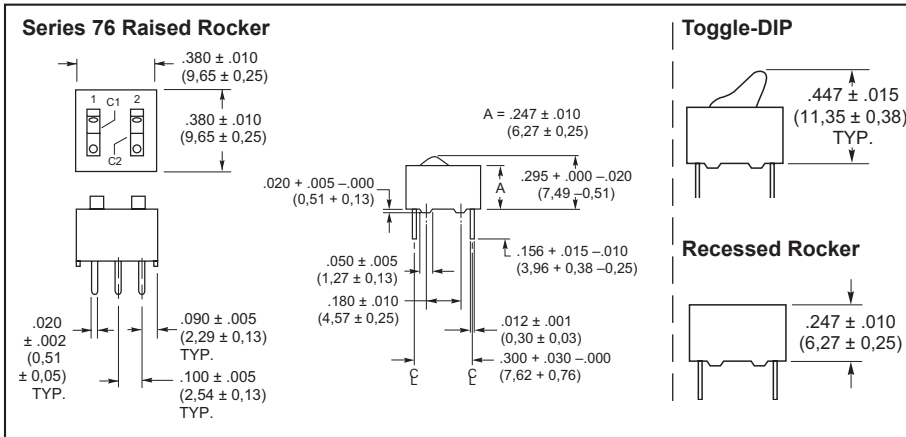


CIRCUITRY: Series 76

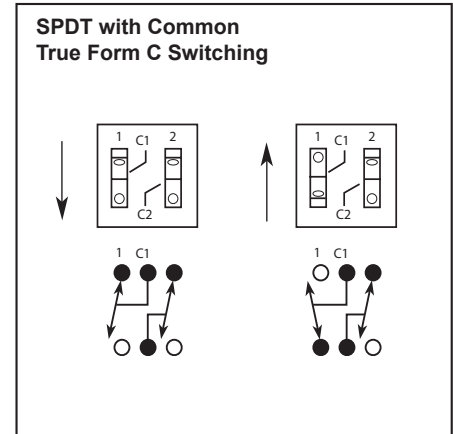

DIMENSIONS: Series 78 in inches (and millimeters)

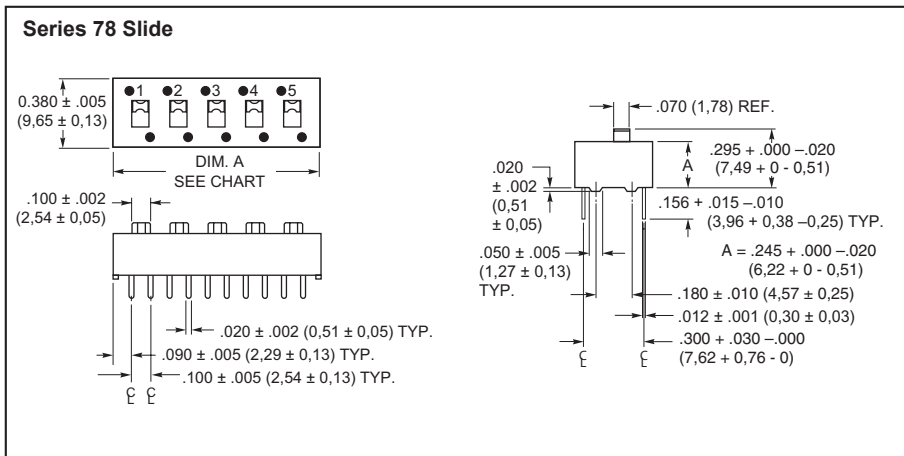

CIRCUITRY: Series 78

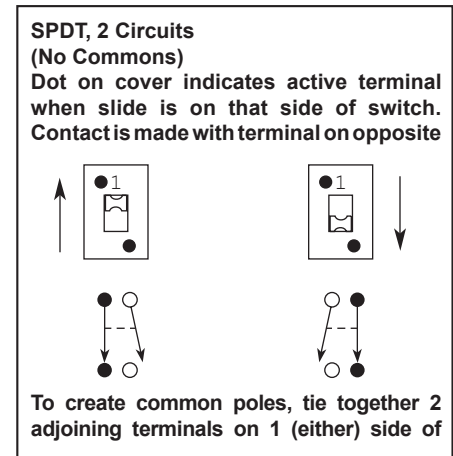

ORDERING INFORMATION

Circuitry	Positions	Length Inches	Length Metric	No./ Tube	Raised Type*	Recessed Rockers*	Toggle-DIP*
SPDT Form C	2	0.380"	9,7mm	27	76SC02T	76RSC02T	76STC02T
	4	0.780"	19,8mm	13	76SC04T	76RSC04T	76STC04T
SPDT 2 Circuits	1	0.280"	7,1mm	35	78J01T	—	—
	2	0.480"	12,2mm	21	78J02T	—	—
	3	0.680"	17,3mm	15	78J03T	—	—
	4	0.880"	22,4mm	12	78J04T	—	—
	5	1.080"	27,4mm	9	78J05T	—	—

ADDITIONAL INFORMATION

See Options and Accessories brochure
 For the most current soldering and cleaning processing guidelines reference Grayhill DIP Switch Processing Information, Bulletin 1234

Available from your local
 Grayhill Distributor.

For prices and discounts, contact a local Sales Office, an authorized local Distributor or Grayhill.

*To order top seal versions, add "S" before the "T" in the Grayhill part number. Not available on Toggle-DIP.