


SSMB P.C. Board Receptacles

Straight Bulkhead Mounted P.C. Board Receptacle


Standard legs
(.125" max panel thickness)

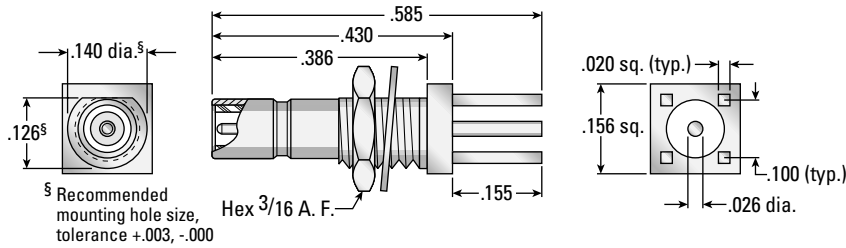

LEG FINISH	AEP P/N
GOLD	7229-1511-000
PRETINNED	7229-1511-012

Straight Bulkhead Mounted P.C. Board Receptacle


Standoff legs
(.125" max panel thickness)

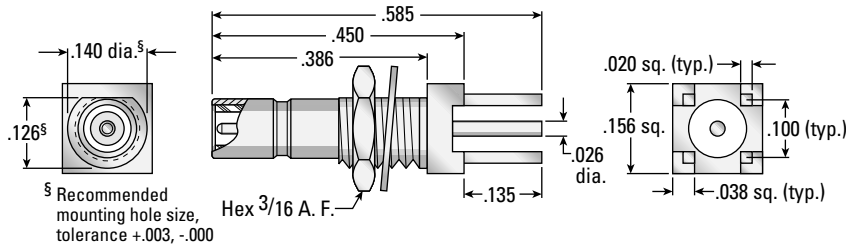

LEG FINISH	AEP P/N
GOLD	7229-1511-050
PRETINNED	7229-1511-040

Straight Bulkhead Mounted P.C. Board Receptacle—Surface Mount


Top mount
(.125" max panel thickness)

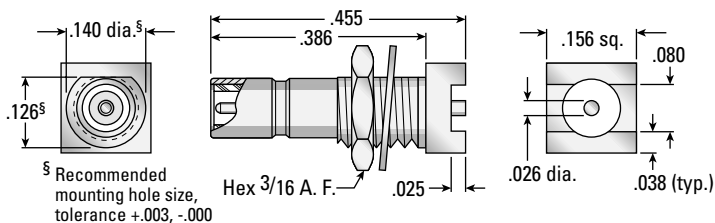

LEG FINISH	AEP P/N
GOLD	7229-1511-015

Straight Bulkhead Mounted P.C. Board Receptacle—Surface Mount

Edge mount
(.125" max panel thickness)

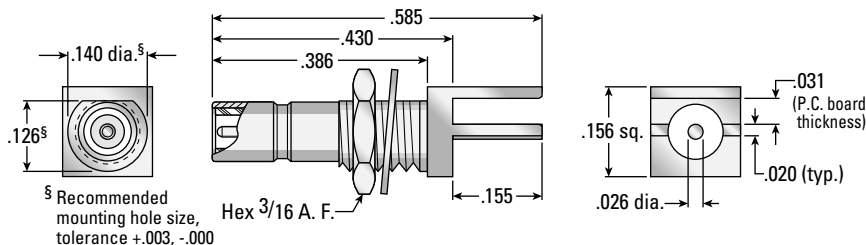

LEG FINISH	AEP P/N
GOLD	7229-1511-060
PRETINNED	7229-1511-061

See page 1 for more information on P.C. board connectors with standoff legs, pretinned legs, and surface mount configurations.