

## STRAIGHT JACKS, FOR SEMI RIGID CABLES

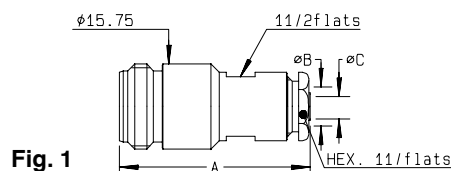


Fig. 1

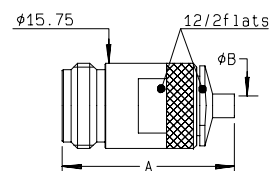


Fig. 2

| cable group | part number          | fig. | dimensions (mm) |      |      | captured center contact | mounting | note        |
|-------------|----------------------|------|-----------------|------|------|-------------------------|----------|-------------|
|             |                      |      | A               | B    | C    |                         |          |             |
| .141"       | <b>R161 227 000</b>  | 1    | 35.5            | 5.6  | 3.65 | NO                      | M06      | Clamp type  |
| .141"       | <b>R161 227 020●</b> | 1    | 35.5            | 5.6  | 3.65 | YES                     | M06      | Clamp type  |
| .141"       | <b>R161 226 020</b>  | 2    | 32              | 3.65 |      | NO                      | M21      | Solder type |

- Upon request

## 25.4 mm SQUARE FLANGE, STRAIGHT JACKS, FULL CRIMP TYPE, FOR FLEXIBLE CABLES (single piece body) (25.4 mm = 1 inch)

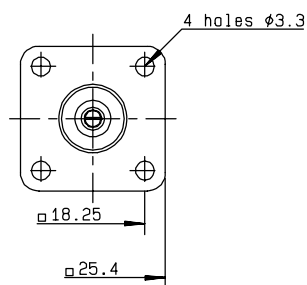


Fig. 1


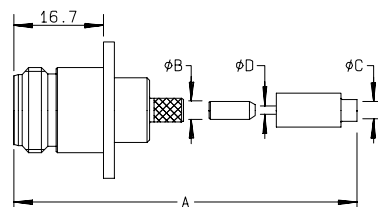



Fig. 2

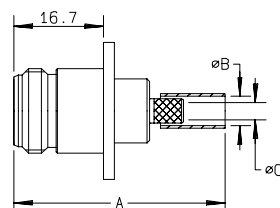

| cable group    | part number         | fig. | dimensions (mm) |       |      |      | captured center contact | mounting | panel |
|----------------|---------------------|------|-----------------|-------|------|------|-------------------------|----------|-------|
|                |                     |      | A               | B     | C    | D    |                         |          |       |
| 2 / 50 / S + D | <b>R161 281 000</b> | 1    | 40.3            | 3.38  | 2.55 | 1    | YES                     | M09      | P01   |
| 2.6 / 50 / S+D | <b>R161 281 300</b> | 1    | 40.3            | 3.38  | 3.25 | 1.63 | YES                     | M09      | P01   |
| 5 / 50 / S     | <b>R161 282 000</b> | 2    | 39.3            | 5.41  | 3.11 |      | YES                     | M12      | P01   |
| 5 / 50 / D     | <b>R161 283 000</b> | 2    | 39.3            | 5.8   | 3.11 |      | YES                     | M12      | P01   |
| 10 / 50 / S    | <b>R161 286 000</b> | 2    | 40.6            | 11.05 | 7.46 |      | YES                     | M10      | P01   |
| 11 / 50 / D    | <b>R161 286 200</b> | 2    | 40.6            | 11.4  | 7.46 |      | YES                     | M10      | P01   |


Note : standard packaging = 50 pieces. For unit packaging, add "W" after the P/N.

## 25.4 mm SQUARE FLANGE, STRAIGHT JACKS, CLAMP TYPE FOR FLEXIBLE CABLES (25.4 mm = 1 inch)

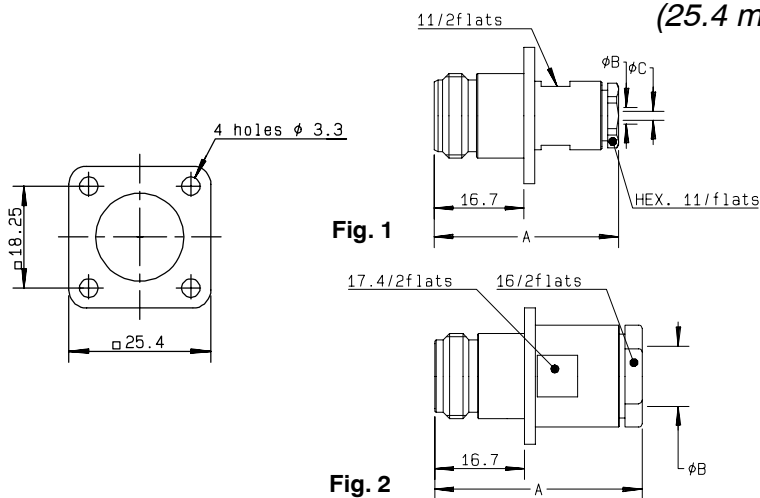

| cable group          | part number         | fig. | dimensions (mm) |      |     | captured center contact | mounting | panel |
|----------------------|---------------------|------|-----------------|------|-----|-------------------------|----------|-------|
|                      |                     |      | A               | B    | C   |                         |          |       |
| 2.6 / 50 / S + D     | <b>R161 252 000</b> | 1    | 34.3            | 3.1  | 1.7 | YES                     | M01      | P01   |
| 5 / 50 / S + D       | <b>R161 256 000</b> | 1    | 35.4            | 5.6  |     | YES                     | M03      | P01   |
| 10 + 11 / 50 / S + D | <b>R161 270 000</b> | 2    | 39.3            | 11.2 |     | YES                     | M05      | P01   |

## 25.4 mm SQUARE FLANGE, STRAIGHT JACKS, EZ FIT TYPE, FOR CORRUGATED CABLES (25.4 mm = 1 inch)

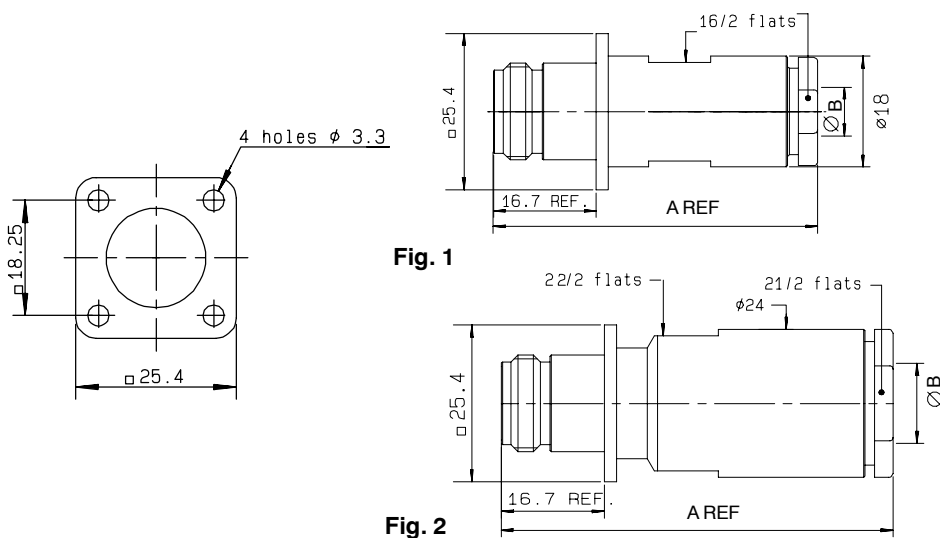

| cable group                   | part number         | fig. | dimensions (mm) |     | captured center contact | mounting | panel |
|-------------------------------|---------------------|------|-----------------|-----|-------------------------|----------|-------|
|                               |                     |      | A               | B   |                         |          |       |
| 1/4" superflexible corrugated | <b>R161 279 007</b> | 1    | 52.7            | 7.9 | YES                     | M22      | P01   |
| 3/8" superflexible corrugated | <b>R161 279 207</b> | 2    | 66              | 11  | YES                     | M22      | P01   |
| 1/2" superflexible corrugated | <b>R161 279 407</b> | 2    | 66              | 14  | YES                     | M22      | P01   |

Note : standard packaging = 50 pieces. For unit packaging, add "W" after the P/N.

## 25.4 mm SQUARE FLANGE, STRAIGHT JACKS, FOR SEMI RIGID CABLES (25.4 mm = 1 inch)

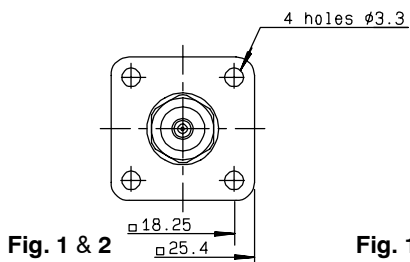


Fig. 1


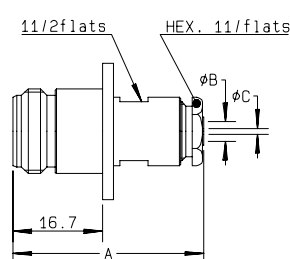


Fig. 2

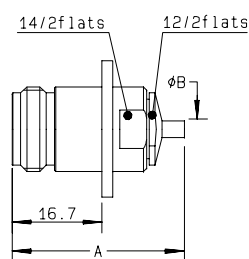

| cable group | part number   | fig. | dimensions (mm) |      |      | captured center contact | mounting | panel | note        |
|-------------|---------------|------|-----------------|------|------|-------------------------|----------|-------|-------------|
|             |               |      | A               | B    | C    |                         |          |       |             |
| .085"       | R161 276 300  | 2    | 32              | 2.25 |      | NO                      | M21      | P01   | Solder type |
| .141"       | R161 277 000  | 1    | 35.5            | 5.6  | 3.65 | NO                      | M06      | P01   | Clamp type  |
| .141"       | R161 277 020● | 1    | 35.5            | 5.6  | 3.65 | YES                     | M06      | P01   | Clamp type  |
| .141"       | R161 277 300  | 2    | 32              | 3.65 |      | NO                      | M21      | P01   | Solder type |
| .250"       | R161 278 300  | 2    | 32              | 6.6  |      | NO                      | M21      | P01   | Solder type |

## BULKHEAD STRAIGHT JACKS, FULL CRIMP TYPE, FOR FLEXIBLE CABLES (PANEL SEALED) (single piece body)

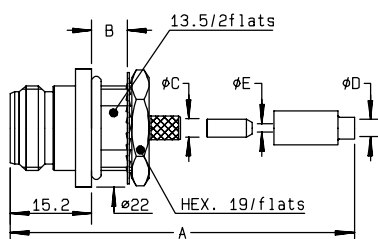


Fig. 1

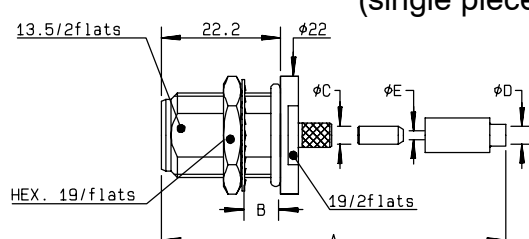


Fig. 2

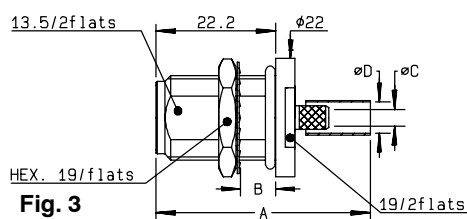


Fig. 3

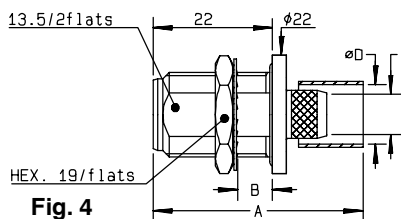


Fig. 4

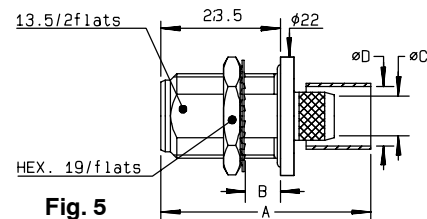


Fig. 5

| cable group      | part number  | fig. | dimensions (mm) |     |       |       |      | captured center contact | mounting | panel | note                                                    |
|------------------|--------------|------|-----------------|-----|-------|-------|------|-------------------------|----------|-------|---------------------------------------------------------|
|                  |              |      | A               | B   | C     | D     | E    |                         |          |       |                                                         |
| 2 / 50 / S + D   | R161 309 000 | 1    | 40.4            | 6.5 | 3.38  | 2.35  | 1    | YES                     | M09      | P10   | Front mount                                             |
| 2 / 50 / S + D   | R161 309 200 | 2    |                 |     |       |       |      | YES                     | M09      | P10   | Rear mount                                              |
| 2.6 / 50 / S + D | R161 311 200 | 1    | 40.4            | 6.5 | 3.38  | 3.25  | 1.63 | YES                     | M09      | P10   | Front mount                                             |
| 2.6 / 50 / S + D | R161 311 300 | 2    |                 |     |       |       |      | YES                     | M09      | P10   | Rear mount                                              |
| 5 / 50 / S       | R161 329 130 | 3    | 39.8            | 6.5 | 3.11  | 5.41  |      | YES                     | M12      | P10   | LMR 200 cable / Rear mount                              |
| 5 / 50 / S       | R161 329 000 | 3    |                 |     |       |       |      | YES                     | M12      | P10   | Rear mount                                              |
| 5 / 50 / D       | R161 329 200 | 3    | 39.8            | 6.5 | 3.11  | 5.8   |      | YES                     | M12      | P10   | Rear mount                                              |
| 10 / 50 / S      | R161 331 000 | 4    | 40.6            | 6.5 | 7.46  | 11.05 |      | YES                     | M10      | P10   | Rear mount                                              |
| 10.3 / 50 / S    | R161 331 060 | 5    | 46.88           | 6.5 | 7.46  | 11.05 |      | YES                     | M11      | P10   | LMR 400 cable / Rear mount                              |
| 11 / 50 / D      | R161 331 200 | 4    | 40.6            | 6.5 | 7.46  | 11.4  |      | YES                     | M10      | P10   | Rear mount                                              |
| 15.2 / 50 / S    | R161 331 400 | 5    | 49.9            | 6.5 | 11.96 | 15.88 |      | YES                     | M11      | P10   | LMR 600 cable / Rear mount / Solder type center contact |

● Upon request

Note : standard packaging = 50 pieces. For unit packaging, add "W" after the P/N.