



ENK Series



AD (Form D)

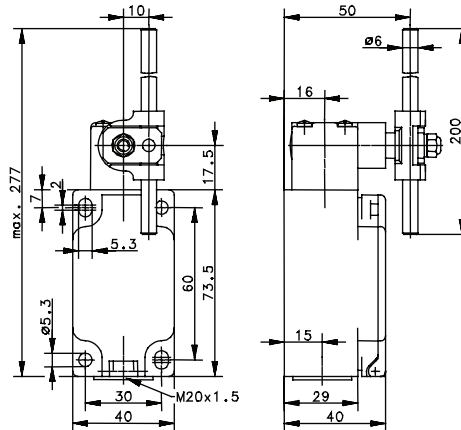

HW RO20

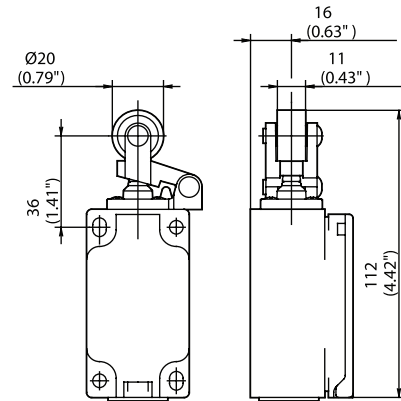


Switching Operation

1 NC / 1 NO Contacts

Slow Action

 608.1137.011
ENK-U1 AD




Snap Action

608.1187.017
ENK-SU1 AD




Slow Action

 608.1121.095
ENK-U1Z HW RO20



Snap Action

 608.1171.096
ENK-SU1Z HW RO20



2 NC Contacts

-

-

-

-

2 NO Contacts

-

-

-

-

**1 NC / 1 NO Contacts
Overlapping**

-

-

-

-

Replacement actuator:

391.8370.739

391.8200.906

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals

* Depending on switching system - see technical information for details



Special features/variants (on request)

- Available with various actuator directions and actuator lengths

Special features/variants (on request)

- Available with black enclosure and various roller diameters

Drawing dimensions in mm