

CAN Termination Datasheet





Order numbers:

Socket (female) 1.04.0075.01000

Plug (male) 1.04.0075.02000

All dimensions in mm

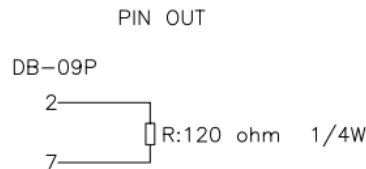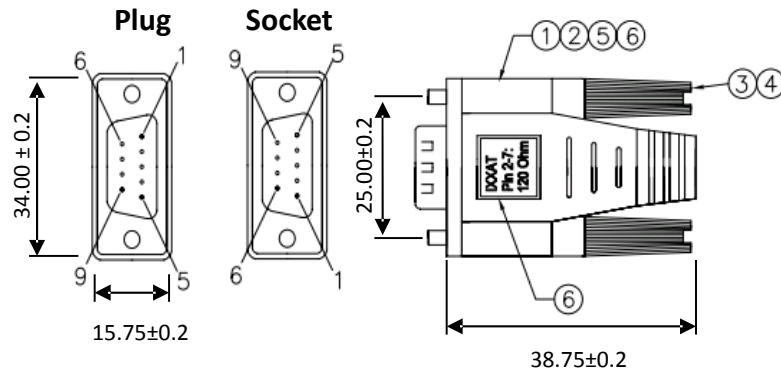

CAN Termination

120 Ohm bus termination for High-Speed CAN systems according to ISO 11898-2; SUB-D9 connector; R_T between pin 2 and 7

Socket (female)
1.04.0075.01000

Plug (male)
1.04.0075.02000



Specification

Contact:	Brass
Contact plating:	Gold plated over nickel
Shell:	Tin plated shell
Current rating:	3 AMP
Dielectric strength:	500V AC for one minute
Insulator resistance:	500MOhm min. at 500V DC
Temperature range:	-55°C to 105°C
Label (6) :	PE
Screw (3):	#4-40UNC E30.5
Resistor (1):	120Ohm 1/4W
Connector (2):	DB-09P
Insulator (4,5):	PVC