


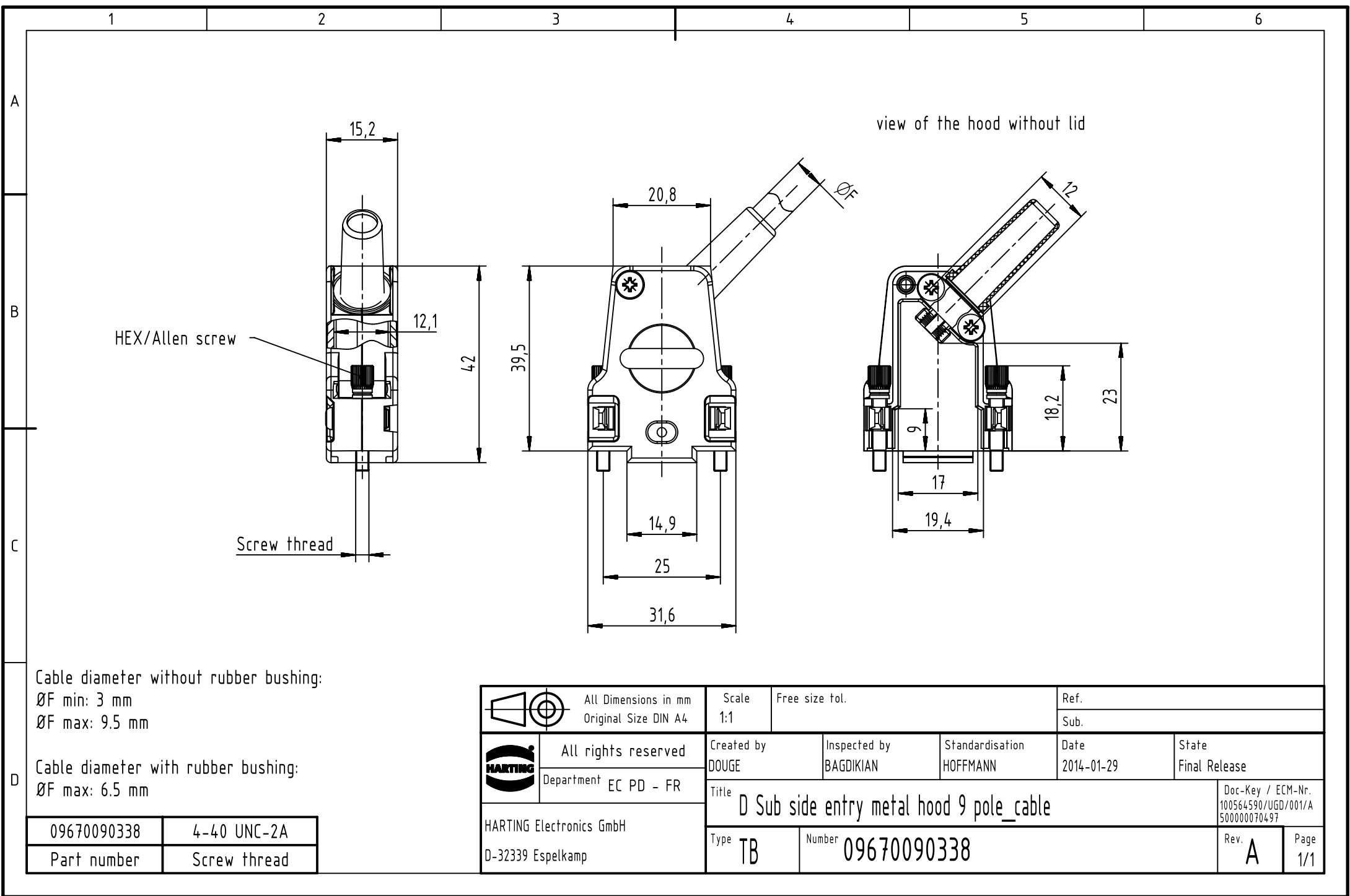

Cable diameter without rubber bushing:  
ØF min: 3 mm  
ØF max: 9.5 mm

Cable diameter with rubber bushing:  
ØF max: 6.5 mm

|             |              |
|-------------|--------------|
| 09670090338 | 4-40 UNC-2A  |
| Part number | Screw thread |

|                                                                                     |  |                                              |  |                                                   |  |                           |  |                             |  |                    |  |                                                          |  |             |  |
|-------------------------------------------------------------------------------------|--|----------------------------------------------|--|---------------------------------------------------|--|---------------------------|--|-----------------------------|--|--------------------|--|----------------------------------------------------------|--|-------------|--|
|  |  | All Dimensions in mm<br>Original Size DIN A4 |  | Scale<br>1:1                                      |  | Free size tol.            |  | Ref.                        |  |                    |  |                                                          |  |             |  |
|                                                                                     |  |                                              |  |                                                   |  |                           |  | Sub.                        |  |                    |  |                                                          |  |             |  |
|  |  | All rights reserved                          |  | Created by<br>DOUGE                               |  | Inspected by<br>BAGDIKIAN |  | Standardisation<br>HOFFMANN |  | Date<br>2014-01-29 |  | State<br>Final Release                                   |  |             |  |
|                                                                                     |  | Department EC PD - FR                        |  | Title<br>D Sub side entry metal hood 9 pole_cable |  |                           |  |                             |  |                    |  | Doc-Key / ECM-Nr.<br>100564590/UGD/001/A<br>500000070497 |  |             |  |
| HARTING Electronics GmbH<br>D-32339 Espelkamp                                       |  |                                              |  | Type<br>TB                                        |  | Number<br>09670090338     |  |                             |  |                    |  | Rev.<br>A                                                |  | Page<br>1/1 |  |