

## INLINE FUSE HOLDER FOR ATO® STYLE BLADE FUSE



### Description

Used with ATO® / FKS Fuse. Supplied with two 4" / 102mm wire leads.


### Ordering Information

| Part Number | Package Size |
|-------------|--------------|
| 0FHA0001ZXJ | 1000         |
| 0FHA0002ZXJ | 1000         |

### Dimensions

Dimensions in mm

**RoHS**

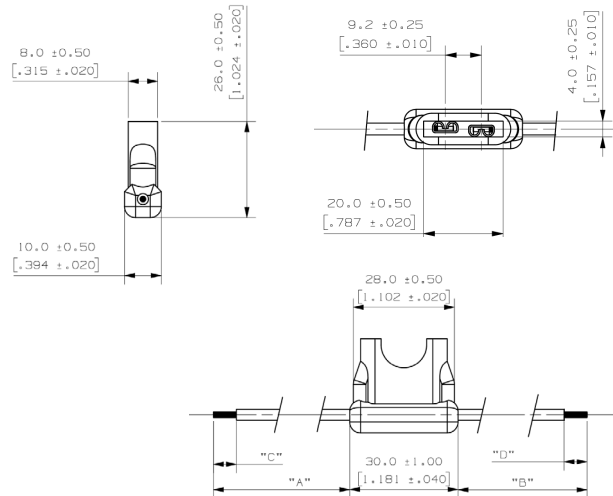

### Ratings

| Part Number | Description                                   | Fuse Rating  |
|-------------|-----------------------------------------------|--------------|
| 0FHA0001_   | 16AWG/1.3mm <sup>2</sup> stranded black wire  | 20A @ 32V DC |
| 0FHA0002_   | 12AWG/3.3mm <sup>2</sup> stranded orange wire | 30A @ 32V DC |

Wire length, color and diameter can be customized upon request. Customization requires minimum order quantities depending on nature of modifications. Please contact your sales representative for details.

## INLINE SPLASHPROOF FUSE HOLDER

for ATO® Style Blade Fuse



### Description

Used with ATO® / FKS Fuse. Supplied with two 4" / 102mm wire leads. Includes protective cover for harsh environment.


### Ordering Information

| Part Number | Package Size |
|-------------|--------------|
| FHAC0001ZXJ | 1000         |
| FHAC0002ZXJ | 1000         |

### Dimensions

Dimensions in mm

**RoHS**

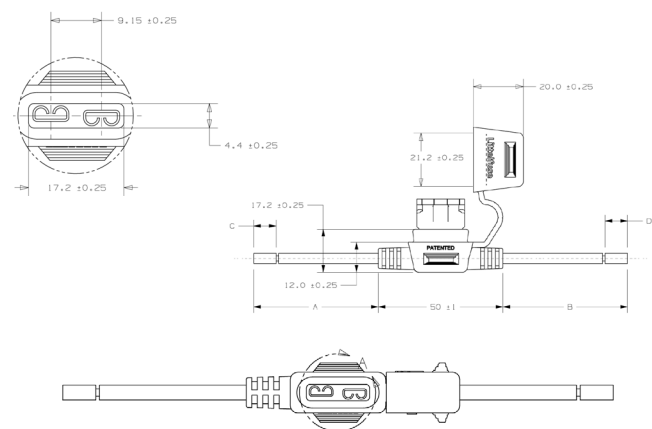

### Ratings

| Part Number | Description                                   | Fuse Rating  |
|-------------|-----------------------------------------------|--------------|
| FHAC0001ZXJ | 16AWG/1.3mm <sup>2</sup> stranded black wire  | 20A @ 32V DC |
| FHAC0002ZXJ | 12AWG/3.3mm <sup>2</sup> stranded orange wire | 30A @ 32V DC |

Wire length, color and diameter can be customized upon request. Customization requires minimum order quantities depending on nature of modifications. Please contact your sales representative for details.