


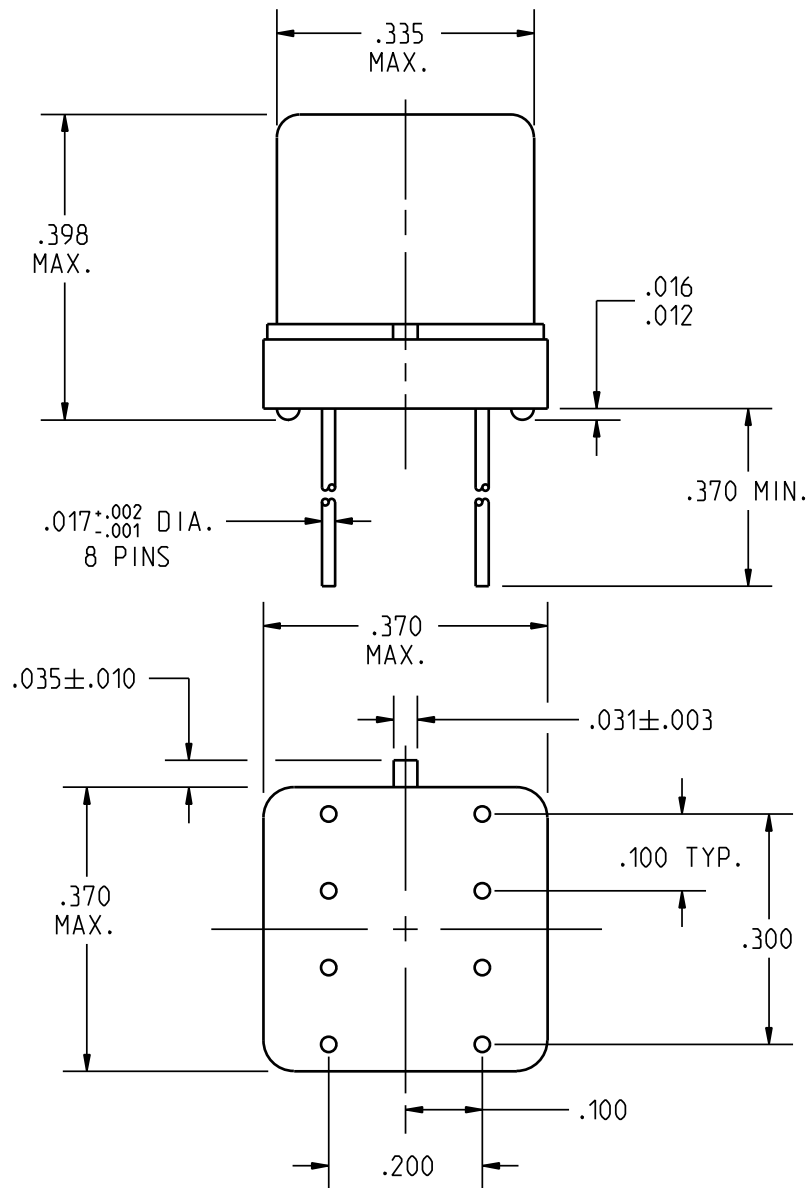


REV. 0

DCO 143868

COIL: @ 25°C
 RESISTANCE 390 OHMS ±10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 7.0 VDC
 MUST RELEASE 4.0 VDC MAX, 0.63 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 Hz TO 3000 Hz @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE TIME 2.0 MS MAX
 RELEASE TIME 4.0 MS MAX
 CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

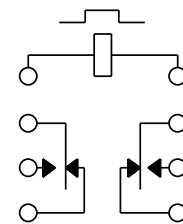

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
 1A 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 08APR04

CK. JERRY C. 4/12/04

CII Technologies
 advanced control electronic solutions

CUST. QPL
 CUST. NO. M39016/9-074L REV.

"JMAC" RELAY

JMAC-12XLS