


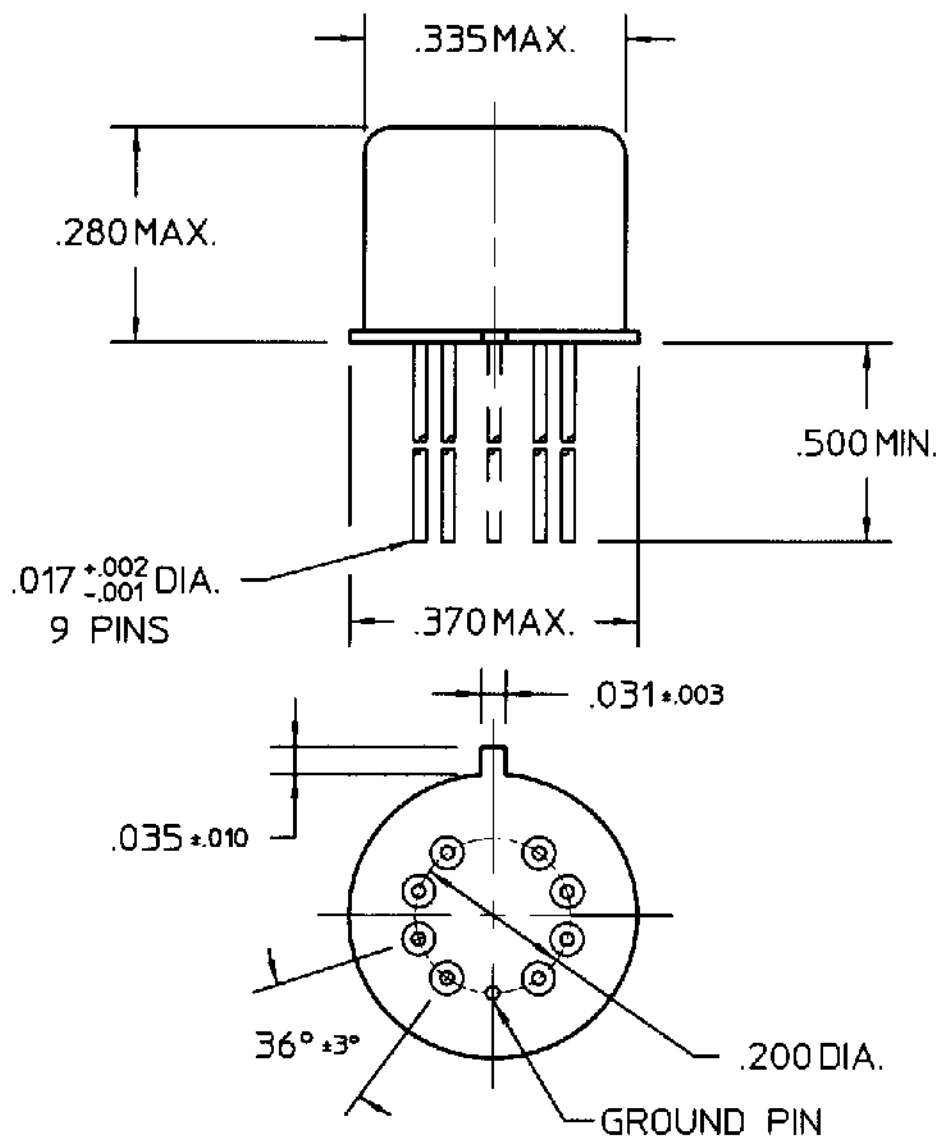

REV. 0
DCO 142077


COIL: @ 25°C
RESISTANCE 390 OHMS $\pm$ 10%
NOMINAL VOLTAGE 12.0 VDC
MUST OPERATE 7.0 VDC
MUST RELEASE 4.0 VDC MAX, 0.63 VDC MIN

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.
RELEASE TIME 4.0 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

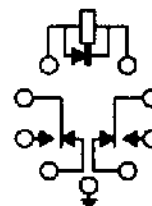

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 6/6/00

Kerry C. 6/6/00



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. OPL
CUST. NO. M39016/15-091L REV.

JMAC RELAY

JMACDG-12XL