
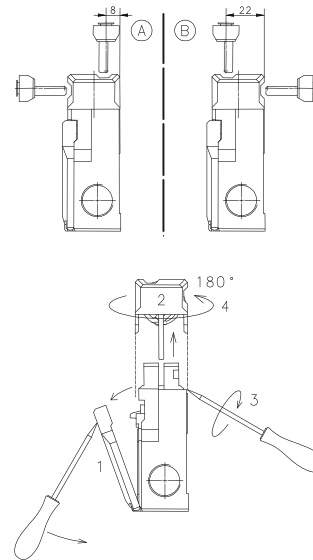


SKC Series

SKC

 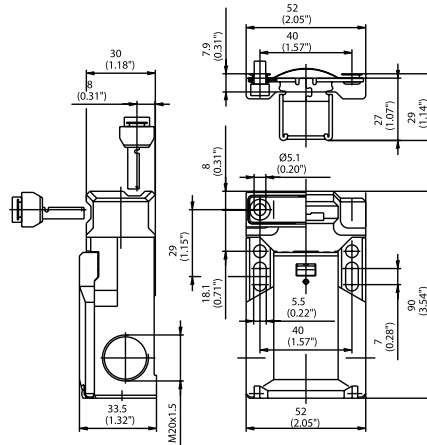


Switching Operation

1 NC / 1 NO Contacts


Slow Action

601.6119.016
SK-U1Z M




High Activation Force

 611.6119.109
SK-U1Z F30 M



Radius Activation

 601.6119.084
SK-U1Z MRU



1 NC Contacts

 
-

-


-

2 NC Contacts


601.6169.036
SK-A2Z M



 601.6169.053
SK-A2Z F30 M




 601.6169.085
SK-A2Z MRU




2 NC / 1 NO Contacts
Overlapping

 
601.6169.026
SK-UV15Z M



 601.6169.061
SK-UV15Z F30 M




 601.6169.086
SK-UV15Z MRU




Replacement actuator keys:

M4 ACTUATOR KEY
391.1452.161

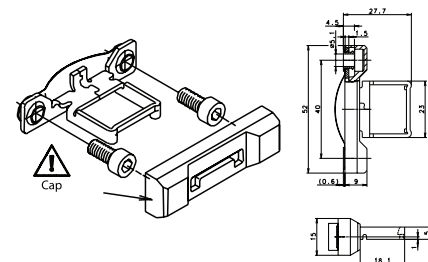

6" Minimum Bend Radius

MRU ACTUATOR KEY
391.1452.058

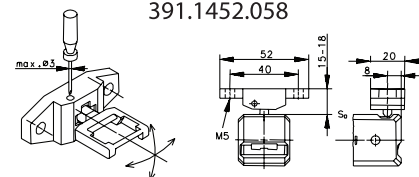

2" Minimum Bend Radius

Technical Information

Maximum Switching Voltage

240V

240V

240V

Max. Switching Amps (up to)*

10A

10A

10A

B10d (up to)*

20 Million

20 Million

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

10 x 10⁵

10 x 10⁶

Switching Frequency

≤ 30/min

≤ 30/min

≤ 30/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

250VAC

250VAC

250VAC

Approvals

* Depending on switching system - see technical information for details



Special features/variants (on request)

- 100 N actuating force on request

Drawing dimensions in mm