

Actuator

03-
810.001



<https://eao.com/p/03-810.001>

Your product:



03-810.001 Actuator

MOUNTING

Mounting cut-out: 21.2 mm x 41.2 mm

Design: flush

ELECTRICAL CHARACTERISTICS

Operating voltage: 10 - 55 V AC

Switching voltage and switching current: 10 VAC ... 55 VAC, 25 mA
10 VDC ... 75 VDC, 15 mA

MECHANICAL CHARACTERISTIC

Weight: 0.06 kg

Tightening torque: Fixing sleeve max. 0.2 Nm, Screw terminal 0.8 Nm

Terminal: Screw terminal

ACOUSTICAL CHARACTERISTICS

Tone frequency: ca. 2.8 kHz

AMBIENT CONDITION

IP Protection: IP40 front side, according to DIN EN 60529

Operating temperature: - 20 °C ... + 60 °C

Storage temperature: - 30 °C ... + 70 °C

CERTIFICATE

Conformities:

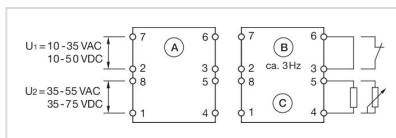
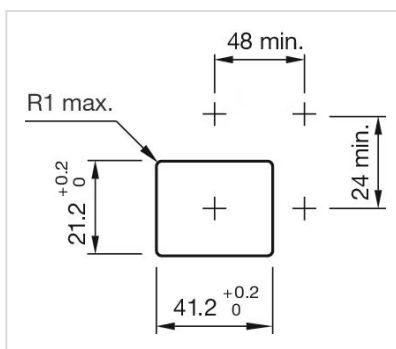
CE, UKCA, 2011 / 65 / EC (RoHS), 2014 / 30 / EU (EMC)

OTHER**Short Description:**

Actuator, 21.2 mm x 41.2 mm, Screw terminal

Buzzer system:

Electronic non-contacting buzzer with IC oscillator

Wiring diagrams:**Mounting cut-outs:****Dimension drawings:**