
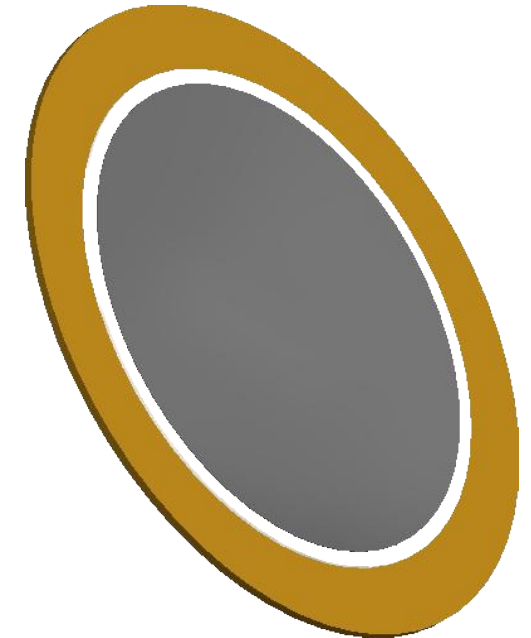


SPECIFICATIONS		
PARAMETERS	VALUES	UNITS
RESONANT FREQUENCY	18,000 ± 2,000	Hz
RESONANT IMPEDANCE (MAX)	1000	Ohm
MAX INPUT VOLTAGE	30	Vp-p
CAPACITANCE @ 100HZ	7,000 ± 30%	pF
PLATE MATERIAL	BRASS	-
OPERATING TEMPERATURE	-20 ~ +60	°C
STORAGE TEMPERATURE	-20 ~ +70	°C

THIS DOCUMENT CONTAINS DATA PROPRIETARY TO PROJECTS UNLIMITED, INC. ANY USE OR REPRODUCTION, IN ANY FORM, WITHOUT PRIOR WRITTEN PERMISSION OF PROJECTS UNLIMITED, INC. IS PROHIBITED.

©2003, Projects Unlimited Inc.

REVISION HISTORY			
LTR	DESCRIPTION	DATE	APPROVED
-	RELEASED FROM ENGINEERING	1/19/2005	
A	REVISED TO INVENTOR 3-D DRAWING TEMPLATE	8/16/2007	B.R.
B	UPDATED CAPACITANCE, IMPEDANCE, DIMENSIONS	9/29/2017	M.L.

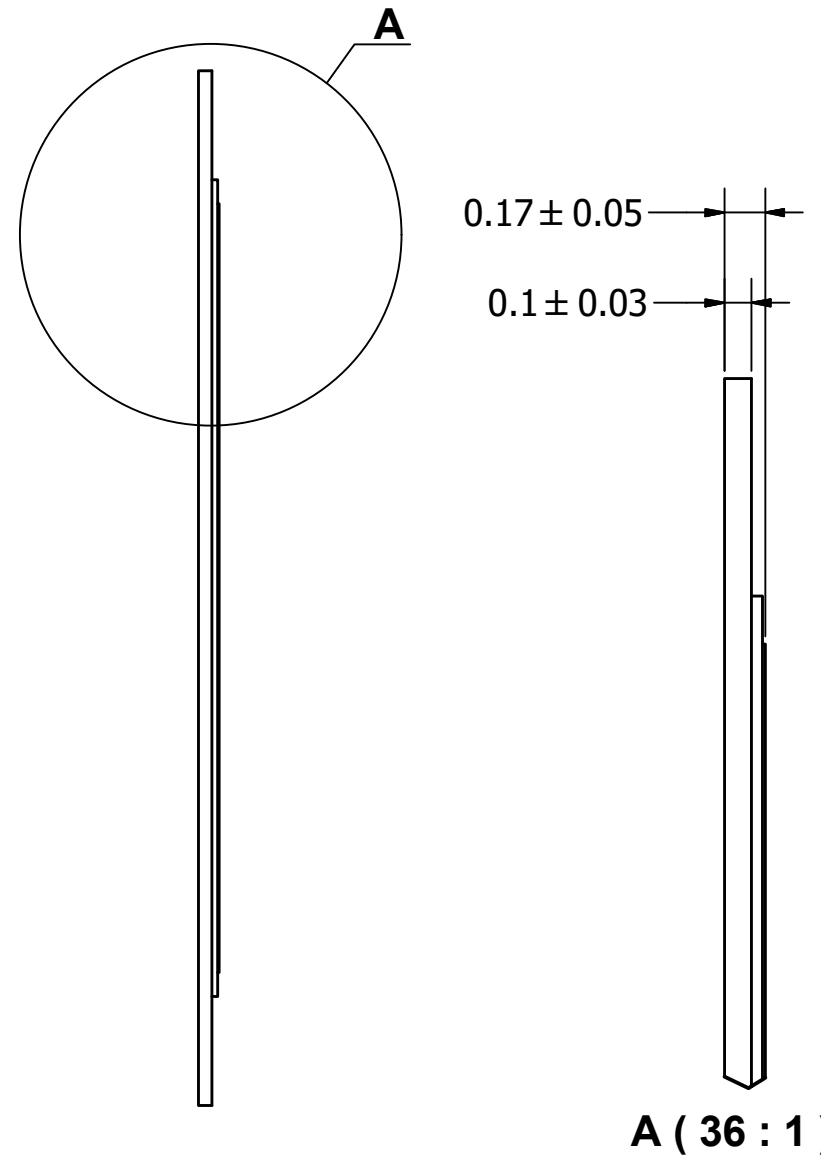


NOTES:

1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. SPECIFICATIONS SUBJECT TO CHANGE OR WITHDRAWAL WITHOUT NOTICE.

1. ALL DIMENSIONS ARE IN MILLIMETERS.

2. SPECIFICATIONS SUBJECT TO CHANGE OR WITHDRAWAL WITHOUT NOTICE.

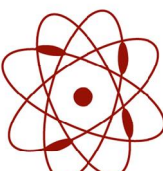UNLESS OTHERWISE SPECIFIED: DIMENSIONS ARE IN MILLIMETERS, TOLERANCES ARE ±0.5 AND ANGLES ARE ±3°.	SIZE A3	Designed by	Date	Checked by	Date	Approved by	Date	Drawn Date	
		R.A.C.	1/19/2005	R.W.	1/19/2005			8/16/2007	
	 pui audio ™ inc a projects unlimited company			AB0818B					
			Bender					Edition -	Sheet 1 / 1
AB0818B.idw									