

5

4

3

2


1

D


C

B


A

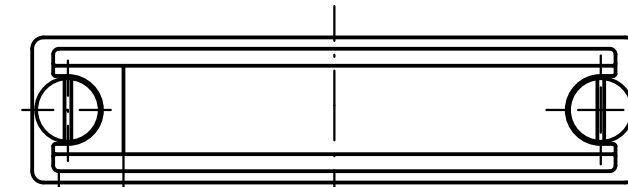

Slotted pan head tapping screws
DIN 7971-ST 2,9x6,5-F
screwing torque=35Ncm +/-5Ncm

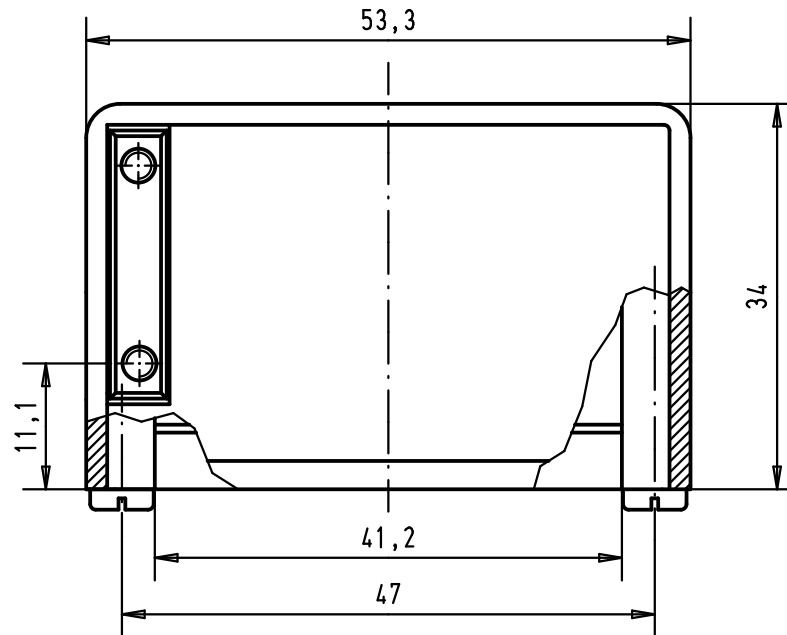

Slotted pan head tapping screws
DIN 7971-ST 2,2x9,5-F
Maximum screwing torque=0,25 mN

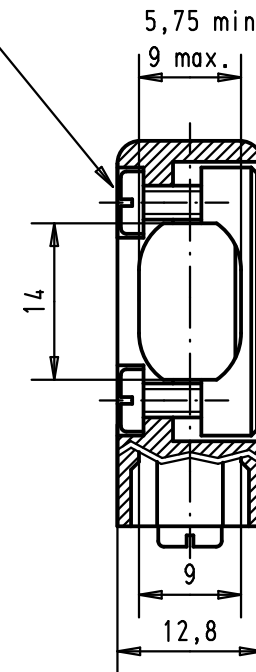

A						Dat.	Name	 All Dim. in mm Orig. Size DIN A 4	D-Sub, Hood 25 poles, for spring or slide locking, side cable entry	Maßstab/ Scale 1.5:1
					Detail.	28-MAR-02	CV			
					Insp.	25-MAY-11	JMDV			
					Stand.					
		EC03223	25-MAY-11	SD						
	09 67 025 0513	Thermoplastic metallized	31861	21-JAN-04	JFB	HARTING EURL F-95972 Paris			TB 0967025051x	Blatt/ Page 1
	09 67 025 0511	Thermoplastic grey RAL 7032	29760	28-MAR-02	CV					
	Part number	Material	Mod.	Dat.	Name					
									Sub.	

