


105/106/125 Series Circuit Board Mount Clips for Midget (13/32") Diameter Fuses

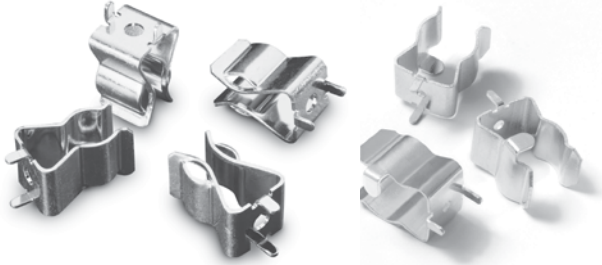

Traditional Type: 105/125 Series

Low Profile Type: 106 Series




Product Characteristics

	105 Series	125 Series	106 Series
Compatible Fuse Size	13/32" Diameter Fuses (Midget Type Fuse)		
Current Levels	15A max	30A max	15A max

Agency Approval


Agency	Agency File Number		
	105 Series	125 Series	106 Series
UL US	E14721		N/A

Product Dimensions

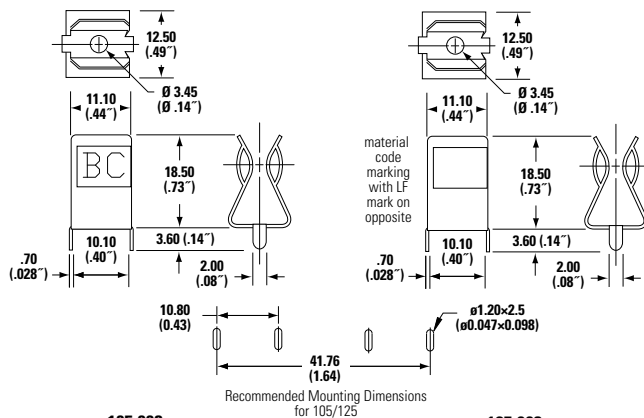

**105 003
Device Dimensions**

**125 003
Device Dimensions**

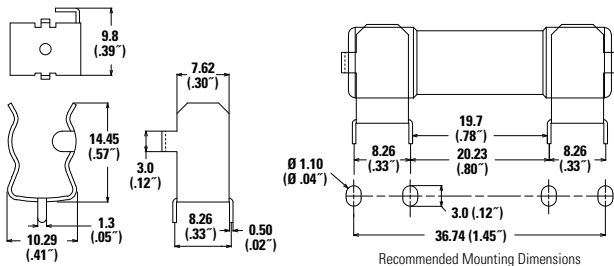

**106 001
Device Dimensions**

Ordering Information

Ordering No.	Catalog No.	Clip Material*	Plating	Style	Packaging
01050003H	105 003	Spring Brass	Tin-plated	Ear	Bulk/100pcs
01250003H	125 003	Beryllium Copper	Tin-plated	Ear	Bulk/100pcs
01060001Z	106 001	Phosphor Bronze	Tin-plated	Ear	Bulk/100pcs

"H" = std. package 100 pcs per pack
"Z" = for bulk package

Additional Information



**Datasheet
105 Series**



**Datasheet
106 Series**



**Datasheet
125 Series**



**Resources
105 Series**



**Resources
106 Series**



**Resources
125 Series**



**Samples
105 Series**



**Samples
106 Series**



**Samples
125 Series**