


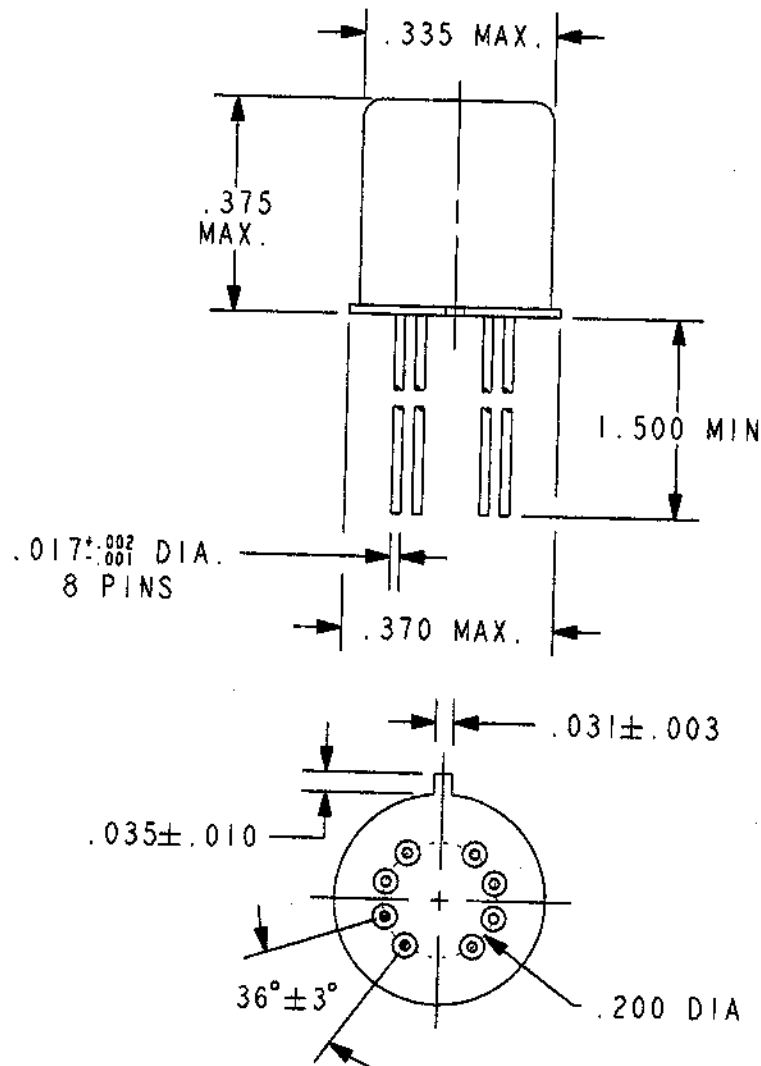

REV. 0

DCO 143385


COIL: @ 25 $^\circ$ C
 RESISTANCE 850 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 7.0 VDC
 MUST RELEASE 4.0 VDC MAX, 0.64 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 3000 Hz @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 $^\circ$ C TO +125 $^\circ$ C

NOTES: OPERATE TIME 4.0 MS MAX.
 RELEASE TIME 2.0 MS MAX.
 CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

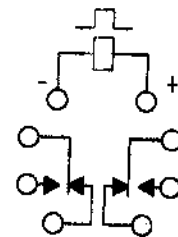

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 1/11/02 *[Signature]* 1/11/02

CII Technologies
 advanced control electronic solutions

CUST. OPL
 CUST. NO. M39016/11-021L REV.

"JMS" RELAY

JMSW-12XL