

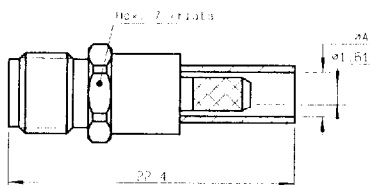


STRAIGHT JACK, FULL CRIMP TYPE, FOR FLEXIBLE CABLE

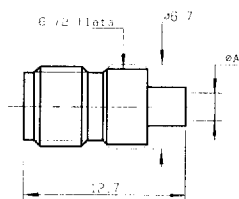

cable group	part number	A	mounting	finish	note
2.6/ 50 / S	R124 236 120	3,25	M 01	BBR	3 piece SMA
2.6/ 50 / S	R124 236 123	3,25	M 01	Gold	
2.6/ 50 / D	R124 233 120	3,5	M 01	BBR	
2.6/ 50 / D	R124 233 123	3,5	M 01	Gold	

STRAIGHT JACK, SOLDER TYPE, FOR SEMI-RIGID CABLE

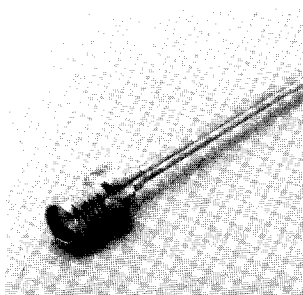

cable group	part number	A	mounting	finish	note
.085	R124 222 000	2,25	M 04	BBR	Non captivated center contact
.085	R124 222 003	2,25	M 04	Gold	
.141	R124 225 000	3,65	M 04	BBR	
.141	R124 225 003	3,65	M 04	Gold	

Standard packaging : 100 pieces