

SUMMARY

Wires

Coax	1
------	---



Image is for illustrative purpose only

Series	0A
Termination type	Male solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	4.00 - 5.10 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FFA*: Straight plug with cable collet and nut for fitting a bend relief
Keying	
Housing Material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Variant	Z : Nut for fitting a bend relief
Weight	7.91 g

Performance

Configuration	0A.275 : 1 Coax (75 Ohm)
Insulator	
Rated Current	

Specifications


Contact Type: Coaxial 75 Ohm (Solder)

Others

Endurance (Shell): 5000 mating cycles
Salt Spray Corrosion: >144 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

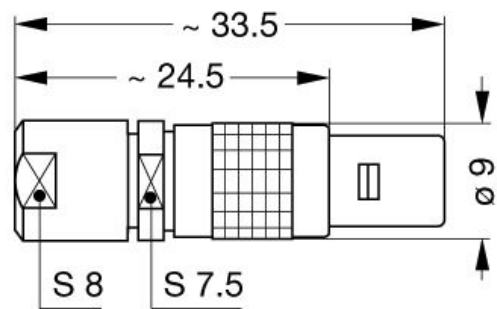

Dimensions

	A	B	L	M	S1	S2
mm.	9	9	37	27.5	7.5	7
in.	0,35	0,35	1,46	1,08	0,30	0,28

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.