


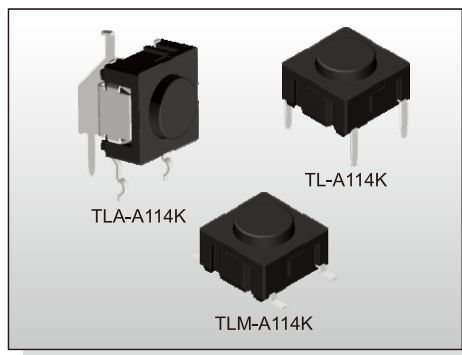

FEATURES

- ※ Sealed
- ※ Long life of 10million
- ※ Variety of actuator lengths


APPLICATION

- ※ Music instrument
- ※ Intercom system
- ※ Industrial

SPECIFICATION

Contact Rating	0.5~50mA, 24V DC
Contact Resistance	30mΩ max.
Insulation Resistance	10MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	300±75gf
Travel	1mm
Operating Life	10,000, 000 cycles
Operating Temp.	-40°C ~ +160°C
Storage Temp.	-40°C ~ +160°C

CIRCUIT

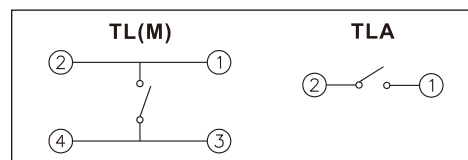

PACKAGE

<Tube>

TL(A): 45 pcs

<Tape & Reel>

TLM: 650 pcs

HOW TO ORDER

TL ☐ - A 1 1 4 K - Q - ☐

Solder Type:
☐=Through Hole
M=S.M.T.
A=Right Angle


Package:
B=Tube
(For Through Hole Type)
T/R=Tape & Reel(For S.M.T. Type)

Halogen Free


Button Color:
Black

Operating Force:
300gf

TL-A114K

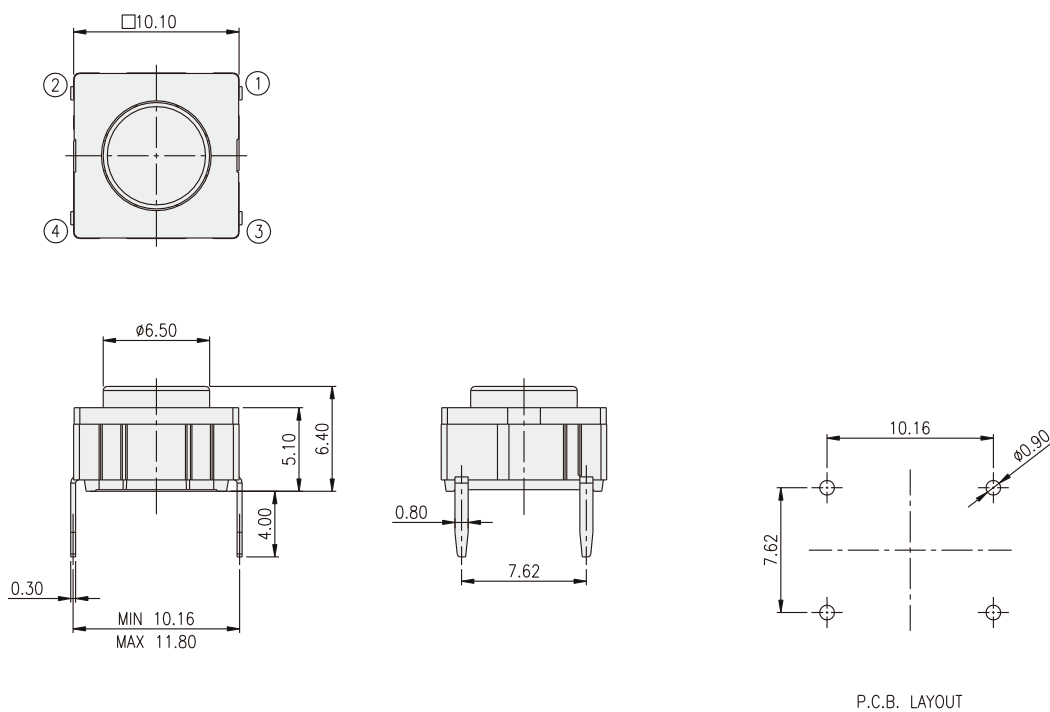

TLM-A114K

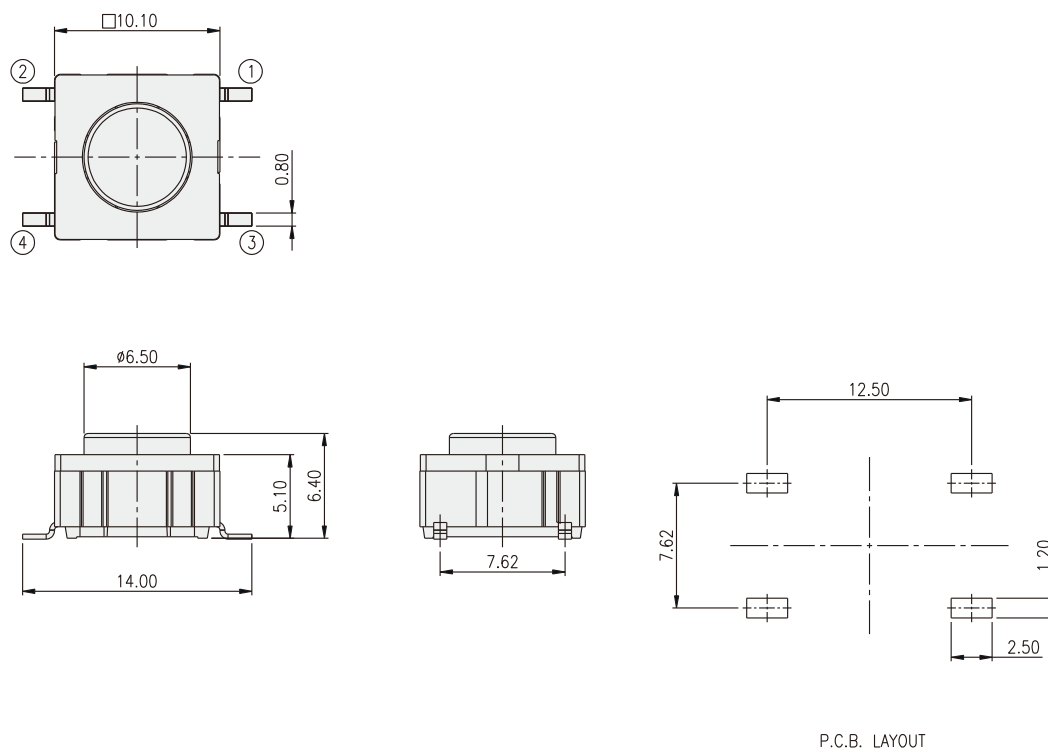

TLA-A114K

