

Series 80 Mighty Mouse Dummy Stowage Receptacle for 805 Connectors 657-079 Ordering Information




Accessories



How To Order			
Sample Part Number	657-079	NF	15
Series	657-079 = Universal Polarity		
Shell Material and Finish	C = Aluminum / Black Anodize (Non-Conductive) RoHS Compliant M = Aluminum / Electroless Nickel NF = Aluminum / Cadmium with Olive Drab ZN = Aluminum / Zinc-Nickel with Olive Drab Chromate ZNU = Aluminum / Zinc-Nickel with Black over Electroless Nickel Z1 = Stainless Steel / Passivated ZB = Stainless Steel / Olive Drab Chromate over Cadmium ZC = Stainless Steel / Zinc Cobalt Alloy / Black Chromate		
Shell Size (See Table II)	8, 9, 10, 11, 12, 13, 15, 18, 19, 21, 23		

These Series 805 dummy stowage receptacles universal polarity provide a safe a convenient place to store and protect cabled connectors when not in use due to routine maintenance or repair of plug cables.

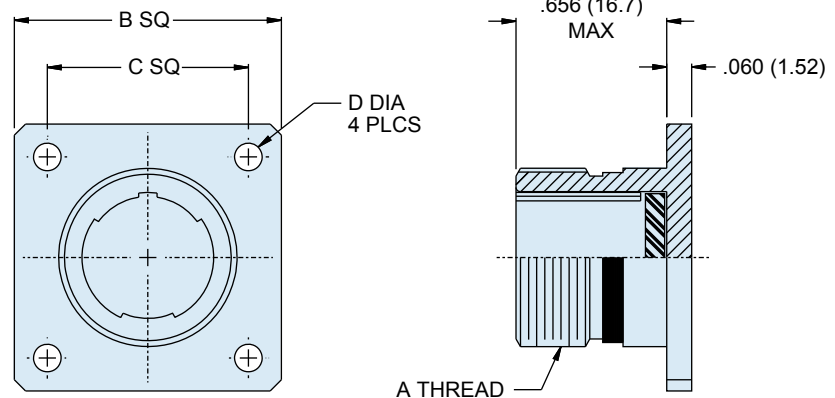

NOTES:

- Glenair 600 series backshell assembly tools are recommended for assembly and installation.

Material and Finish:

- Receptacle: Al Alloy or SST/
- Seal: Fluorosilicone

Table II: Dimensions							
Shell Size	A Thread 2A	B Sq		C Sq		D Dia	
		in.	mm.	in.	mm.	in.	mm.
8	.5000-.1P-.3L-TS	.850	21.59	.660	16.76	.097 .091	2.46 2.31
9	.5625-.1P-.3L-TS	.913	23.19	.723	18.36		
10	.6250-.1P-.3L-TS	.975	24.77	.785	19.94		
11	.6875-.1P-.3L-TS	1.039	26.39	.848	21.54		
12	.7500-.1P-.3L-TS	1.099	27.91	.909	23.09		
13	.8125-.1P-.3L-TS	1.163	29.54	.973	24.71	.131 .125	3.33 3.18
15	.9375-.1P-.3L-TS	1.288	32.72	1.058	26.87		
18	1.1250-.1P-.3L-TS	1.475	37.47	1.255	31.88		
19	1.1870-.1P-.3L-TS	1.537	39.04	1.327	33.71		
21	1.3125-.1P-.3L-TS	1.663	42.24	1.452	36.88		
23	1.4375-.1P-.3L-TS	1.787	45.39	1.570	39.88		

Dimensions in Inches (millimeters) are subject to change without notice.