



ENK Series

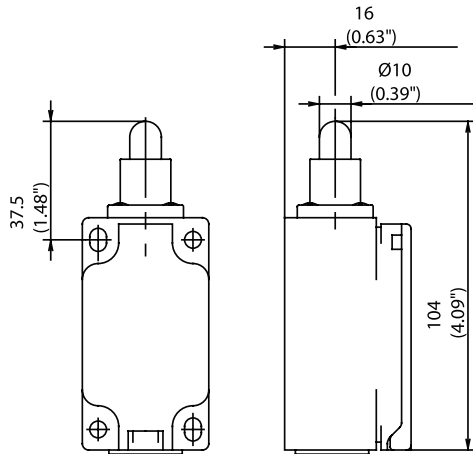

IW (Form B)



RIW (Form C)

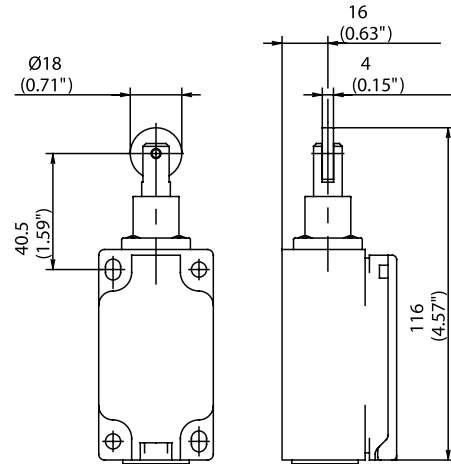


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 608.1102.001
ENK-U1Z IW




Snap Action

 608.1152.007
ENK-SU1Z IW




Slow Action

 608.1117.002
ENK-U1Z RIW



Snap Action

 608.1167.008
ENK-SU1Z RIW




2 NC Contacts

-

-

 608.1817.281
ENK-A2Z RIW



-

2 NO Contacts

-

-

-

 
-

**1 NC / 1 NO Contacts
Overlapping**

-

-

608.1317.307
ENK-UV1Z RIW



-

Replacement actuator:

391.8020.660

391.8170.661

Technical Information

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Max. Switching Amps (up to)*	10A	10A
B10d (up to)*	20 Million	20 Million
Mechanical Service Life (up to)*	10 x 10 ⁶	10 x 10 ⁶
Switching Frequency	≤ 100/min	≤ 100/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP65	IP65
Utilization Category (up to)*	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	400VAC	400VAC

Approvals



Special features/variants (on request)

- Available with black enclosure and following contacts:
3 NC contacts

Slow Action

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Max. Switching Amps (up to)*	10A	10A
B10d (up to)*	20 Million	20 Million
Mechanical Service Life (up to)*	10 x 10 ⁶	10 x 10 ⁶
Switching Frequency	≤ 100/min	≤ 100/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP65	IP65
Utilization Category (up to)*	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	400VAC	400VAC



Special features/variants (on request)

- Available for high temperature range and following contacts:
3 NC contacts

Drawing dimensions in mm