


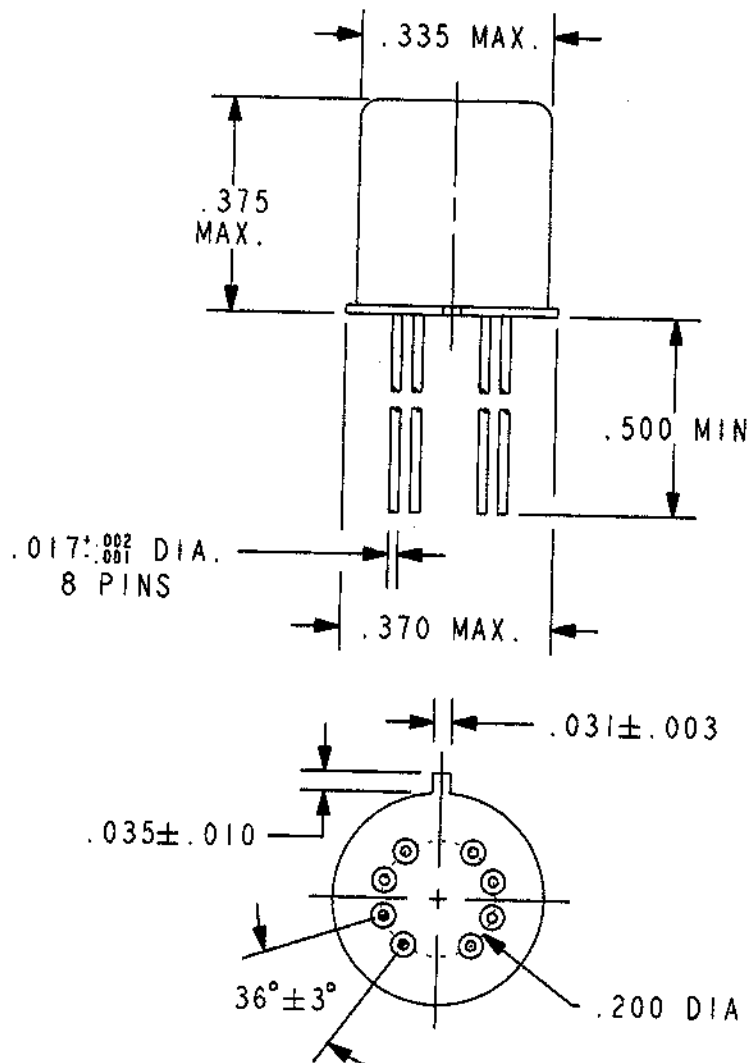

REV. 0
DCO 143385

COIL: @ 25°C
RESISTANCE 200 OHMS ±10%
NOMINAL VOLTAGE 6.0 VDC
MUST OPERATE 3.4 VDC
MUST RELEASE 2.0 VDC MAX, 0.28 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 3000 Hz @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.

RELEASE TIME 7.5 MS MAX.

CONTACT STABILIZATION TIME 2.0 MS MAX.

CUSTOMER DATA SHEET

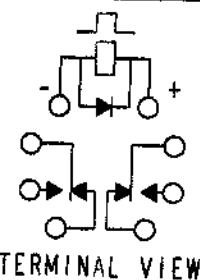

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 1/11/02 CK. *[Signature]* 1/11/02

CII Technologies
advanced control electronic solutions

CUST. OPL
CUST. NO. M39016/16-034P REV.

"JM5CD" RELAY

JM5CD-6XP