




(2,00mm) .0787"

MTMM SERIES

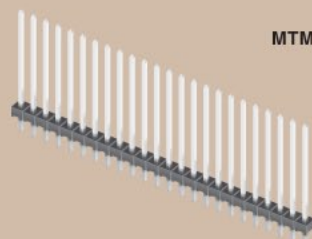

MTMM-114-05-T-Q-225

MTMM-124-14-L-S-600



MTMM-108-07-G-D-200

MODIFIED THROUGH-HOLE HEADER

SPECIFICATIONS

For complete specifications see www.samtec.com?MTMM

Insulator Material:

Black Liquid Crystal Polymer

Terminal Material:

Phosphor Bronze

Plating:

Sn or Au over 50µ" (1,27µm) Ni

Current Rating:

3A @ 80°C ambient

Operating Temp Range:

-55°C to +105°C with Tin;

-55°C to +125°C with Gold

RoHS Compliant:

Yes

Lead-Free Solderable:


Yes



Mates with:
CLT, SQT, SQW, ESQT,
TLE, SMM, MMS, TCSD




Board Stacking

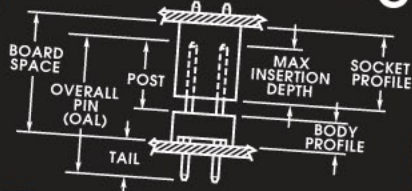


Choice of
single, double or
quad row

Specify post
height in (0,13mm)
.005" increments

 ALSO AVAILABLE



Paste In Hole
(PIH) processing.
Contact Samtec
ASP Group.

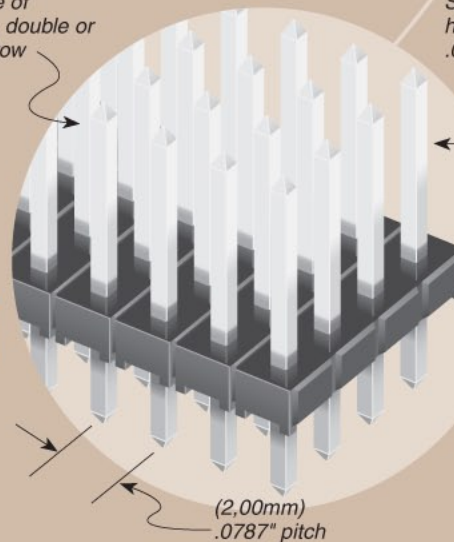

MTMM

1 NO. PINS PER ROW

LEAD STYLE


PLATING OPTION

ROW OPTION

POST HEIGHT

OPTION

01 thru 50

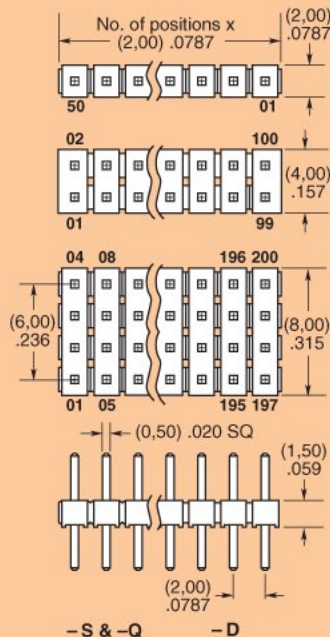

Specify
LEAD
STYLE
from
chart.

-F
= Gold flash on post, Matte Tin on tail

-L
= 10µ" (0,25µm) Gold post, Matte Tin on tail

-G
= 20µ" (0,51µm) Gold post, Gold flash on tail

-T
= Matte Tin

-S
= Single Row

-D
= Double Row

-Q
= Quad Row

-“XXX”
= Post Height in inches (0,13mm) .005" increments
Example:
-070
= (1,78mm) .070"

-“XXX”
= Polarized Position
Specify position of omitted pin

LEAD STYLE	OAL
-02	(6,48) .255
-03	(7,67) .302
-04	(8,20) .323
-05	(9,58) .377
-06	(10,08) .397
-07	(11,58) .456
-08	(12,09) .476
-09	(13,59) .535
-10	(14,10) .555
-11	(15,09) .594
-12	(15,60) .614
-13	(17,09) .673
-14	(19,08) .751
-15	(21,08) .830

Note: Other Gold plating options available. Contact Samtec.

Note: This Series is non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC SILICON VALLEY • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
 SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683